


DPAN L (910 200)


Visual remote indicator for surge protective devices (SPDs)
 Current-saving LEDs with high luminosity
 Easy mounting



Figure without obligation

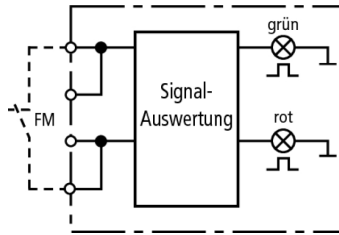

Basic circuit diagram DPAN L

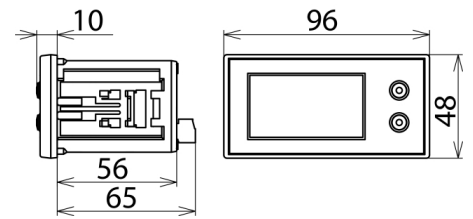

Dimension drawing DPAN L

VV-Highlights

- Visual remote indicator for surge protective devices (SPDs)
- Low energy consumption due to current-saving LEDs
- Easy installation

Type Part No.	DPAN L 910 200
Voltage supply	2x 1.5 V AA batteries
Operating state/fault indication	green LED (flashing) / red LED (flashing)
Flashing frequency	0.1 s on / 1.3 s off
Enclosure material	noryl
Degree of protection (front / rear side)	IP 40 / IP 20
Operating temperature range (T _U)	-25°C...+60°C
Mounting dimensions	92 x 45 mm
Dimensions	96 x 48 x 75 mm
Weight	140 g
Customs tariff number	85389091
GTIN	4013364144019
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.