


## Plateswitches

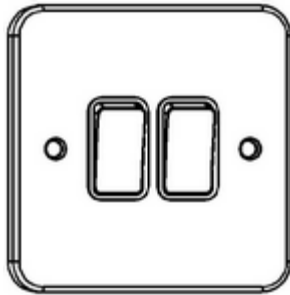

### Description

This stylish range is easy to install, with clear white terminal markings and the frontplates are supplied in protective bags.

### Features

- X-rated for switching inductive or fluorescent loads without de-rating
- supplied with back box
- concave rockers
- only one size 4mm screw driver needed
- clear white terminal markings
- terminals have tapered lead-ins
- captive and backed out terminals
- front plate comes in protective bag
- range can be expanded using Gridswitch range
- 25 year guarantee

### Range

1g 2w	M1203
2g 2w	M1204
3g 2w	M1205

### Technical Specification

voltage rating	250Vac
current rating	10A
contact gap	3mm
size 1g	78mm x 78mm
depth	46mm

### Back Boxes

	knockouts	
	sides	back
1g	5	1

- all knockouts are 20mm dia.

no user serviceable parts

### Standards

- BS EN 60669-1:2000

### Terminal Capacity

	1mm <sup>2</sup>	1.5mm <sup>2</sup>	2.5mm <sup>2</sup>	4mm <sup>2</sup>
L	5	4	2	1

## DETA

Kingsway House, Laporte Way  
Luton, Beds LU4 8RJ UK  
Tel. +44 1582 544 500 Fax: +44 1582 544 501  
Technical Helpline +44 1582 544 548