



Busbar 10 x 10 mm .394 x .394" for ground wire

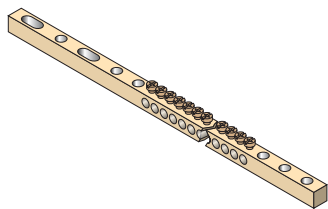

A : Ø 6,5 mm
B : 6,5 x 14,5 mm
C : Ø 6,5 mm
D : Ø 5,5 mm
E : M4 slotted Pozidriv cruciform head screw

BTI

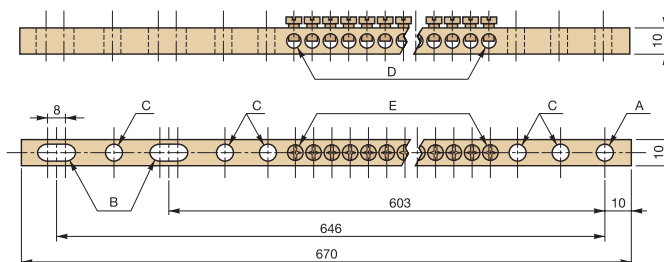


Mounting with screw/nut system - hole type **A** side : Ø 6,5 mm - oblong hole type **B** side : 6,5 x 14,5 mm
Connections :
5 holes type **C** : Ø 6,5 mm for solid/stranded cables screw/nuts connection system
74 holes type **D** : Ø 5,5 mm for solid/stranded cables screw/nuts connection system
secured by 74 screws type **E** : slotted Pozidriv cruciform head

Type	P/N	Characteristics	IEC	UL	CSA
BTI	0179 839.04	Rated current Wire size - Screw - Screw / nut Recommended torque Screw 3 mounting holes : - 2 oblong holes - 1 hole	125 A 74 x 0,75 to 10 mm ² 5 x Ø 6,5 mm 0,7 Nm slotted Pozidriv cruciform 6,5 x 14,5 mm Ø 6,5 mm		

Bars with base for ground wire

DIN 3

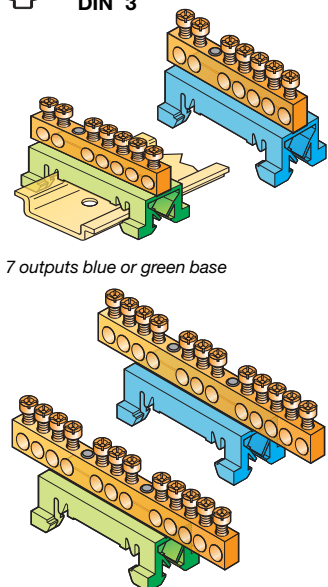


7 outputs blue or green base

12 outputs blue or green base

PR30 35 x 7,5 x 1 0173 220.05
PR4 35 x 15 x 2,3 0168 500.12
PR5 35 x 15 x 1,5 0101 598.26
Other rails : see Accessories section


DBTI

7 outputs

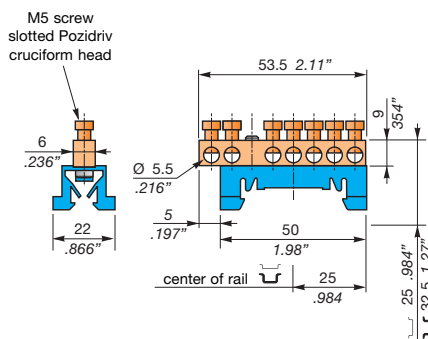

Mounting on DIN 3 rail

12 outputs

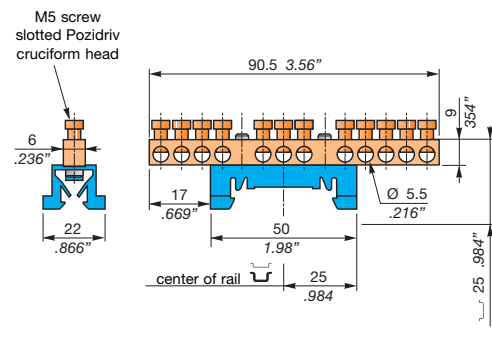

Mounting on DIN 3 rail

Type	P/N	Characteristics	IEC	UL	CSA
7 outputs blue base DBTI	RAU0356 100.15	Rated current Wire size - Screw - Screw / nut Recommended torque Screw 3 mounting holes : - 2 oblong holes - 1 hole	125 A 74 x 0,75 to 10 mm ² 5 x Ø 6,5 mm 0,7 Nm slotted Pozidriv cruciform 6,5 x 14,5 mm Ø 6,5 mm		
7 outputs green base DBTI	RAU0356 101.02				

Type	P/N	Characteristics	IEC	UL	CSA
12 outputs blue base DBTI	RAU0356 102.03	Rated current Wire size - Screw - Screw / nut Recommended torque Screw 3 mounting holes : - 2 oblong holes - 1 hole	125 A 74 x 0,75 to 10 mm ² 5 x Ø 6,5 mm 0,7 Nm slotted Pozidriv cruciform 6,5 x 14,5 mm Ø 6,5 mm		
12 outputs green base DBTI	RAU0356 103.04				

Type	P/N	Characteristics	IEC	UL	CSA
7 outputs blue base DBTI	RAU0356 100.15	Rated current Wire size - Screw clamp - Max. wire size Torque on screw Screw	1.5 Nm 7 outputs 10 mm ² M5	13.3 lb.in 7 outputs 10 mm ² M5	13.3 lb.in 7 outputs 10 mm ² M5
7 outputs green base DBTI	RAU0356 101.02				

Type	P/N	Characteristics	IEC	UL	CSA
12 outputs blue base DBTI	RAU0356 102.03	Rated current Wire size - Screw clamp - Max. wire size Torque on screw Screw	1.5 Nm 12 outputs 10 mm ² M5	13.3 lb.in 12 outputs 10 mm ² M5	13.3 lb.in 12 outputs 10 mm ² M5
12 outputs green base DBTI	RAU0356 103.04				