




Electrical Commercial and Industrial

3M™ Highland™ Nylon Fully Insulated Female Disconnect Terminal FDI14-250Q, AWG 16-14, 25/bag

UPC# 00051128600016 3M Product Number FDI14-250Q 3M ID 80611602626

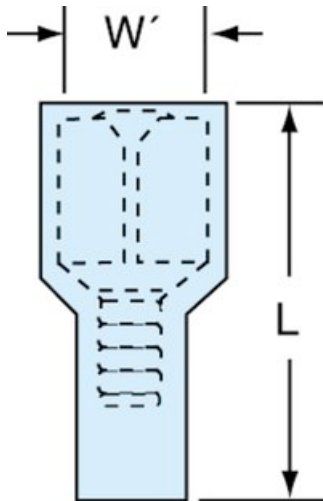

This female disconnect accepts a wire range of 16-14 AWG, a .250 and has a case quantity of 10 bags.

Like

Be the first of your friends to like this.

Overview

Support

Specifications

Agency Approvals	UL and CSA
Barrel Inside Diameter	0.08 Inch
Barrel Length	0.25 Inch
Barrel Style	Butted
Brand	Highland
Conductor Sizes	16 - 14 AWG
CSA File Number	LR22190
Diameter (D)	0.23 Inch
Fastener Orientation	Female
Insulation Material	Nylon
Length (L)	0.87 Inch

Mates with Male Tab Width (W')	0.25 Inch
Maximum Insulation Outer Diameter	0.145 Inch
Packaging	25 per bag
Pad Width	0.25 Inch
Terminal Style	Fully Insulated
Terminal Type	Disconnect
Thickness	0.032 Inch
UL File Number	E70512
Width (W)	0.37 Inch