


Datasheet

New 5.08mm Plug with Flanges 15A 2 way

RS Stock 874-4742



Dimensions: (mm)

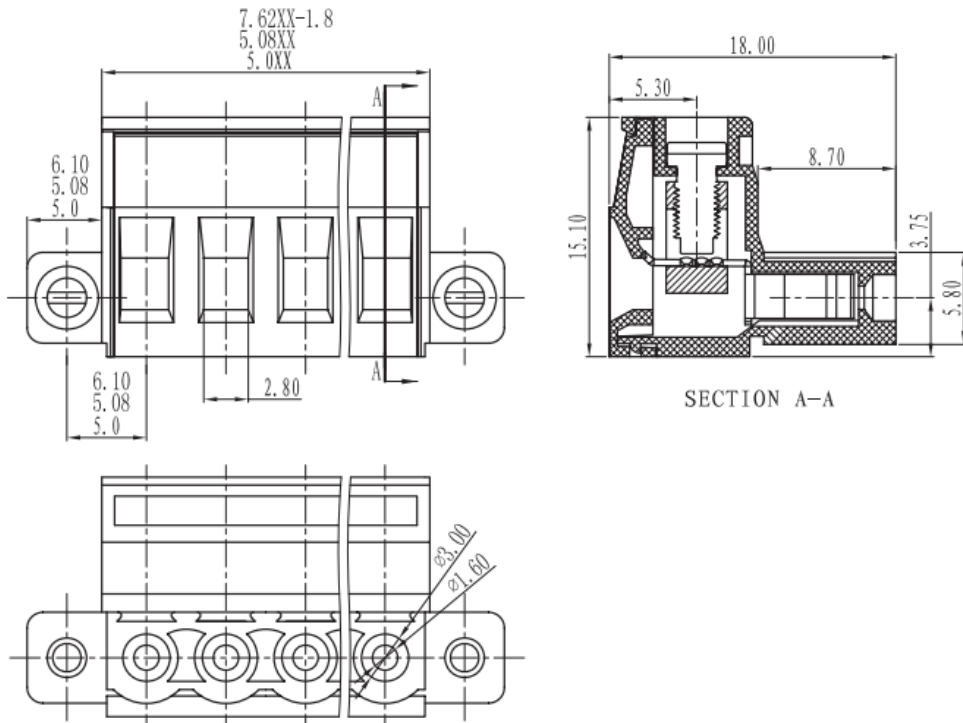



ENGLISH

Specifications

Electrical

Standard: UL IEC
Rated voltage: 300V 320V
Rated current: 15A 20A
Contact resistance: $20\text{m}\Omega$
Wire range: 28-14AWG 2.5mm^2
Withstanding voltage: AC2000V/1Min
Insulation resistance: $500\text{M}\Omega$ /DC500V

Mechanical

Temp.Range: $-40^{\circ}\text{C}\sim+105^{\circ}\text{C}$
Torque: 0.5Nm (4.51lb`in)
Strip length: 7-8mm

Dimensions

Pitch: 5.00mm, 5.08mm, 7.62mm
Poles: 2P-24P

Material

Housing: PA66, UL94V-0
Screws: M3.0, steel Zinc plated
Wire guard: Brass, Ni plated
Clamp: Phosphor bronze, Ni plated