

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [10-01-3026](#)
Status: **Active**
Overview: SPOX™ Wire-to-Board Connectors
Description: 5.08mm Pitch SPOX™ Crimp Terminal Housing, 2 Circuits

Documents:

| | |
|---|---|
| 3D Model | Product Specification PS-5197-005 (PDF) |
| Drawing (PDF) | RoHS Certificate of Compliance (PDF) |
| Product Specification PS-5197-001 (PDF) | |

Agency Certification

| | |
|-----|-----------|
| CSA | LR19980 |
| TUV | R72090224 |
| UL | E29179 |

General

| | |
|----------------|--|
| Product Family | Crimp Housings |
| Series | 5197 |
| Application | Signal, Wire-to-Board |
| Overview | SPOX™ Wire-to-Board Connectors |
| Product Name | SPOX™ |
| UPC | 800753612631 |

Physical


| | |
|-------------------------------|-----------------|
| Circuits (maximum) | 2 |
| Color - Resin | Natural |
| Flammability | 94V-2 |
| Gender | Female |
| Glow-Wire Compliant | No |
| Material - Resin | Nylon |
| Net Weight | 766.600/mg |
| Number of Rows | 1 |
| Packaging Type | Bag |
| Panel Mount | No |
| Pitch - Mating Interface | 5.08mm |
| Stackable | No |
| Temperature Range - Operating | -40°C to +105°C |

Material Info

| | |
|-----------------|---------|
| Old Part Number | 5197-02 |
|-----------------|---------|

Reference - Drawing Numbers

| | |
|-----------------------|--|
| Product Specification | PS-5197-001, PS-5197-005, RPS-5281-001 |
| Sales Drawing | SD-5197-N |

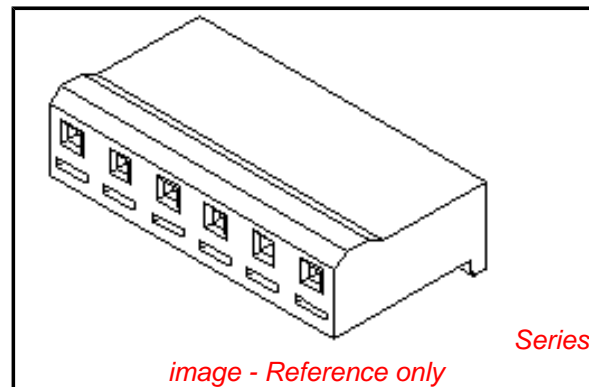

EU RoHS

ELV and RoHS Compliant
REACH SVHC Contains SVHC: No
Low-Halogen Status Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[5197Series](#)

Mates With

[5279](#) , [5280](#) , [5281](#) , [5282](#)

Use With

[5194](#) , [5225](#)