


Busch-Blind control II
Inserts for flush-mounted devices
Basic blind insert

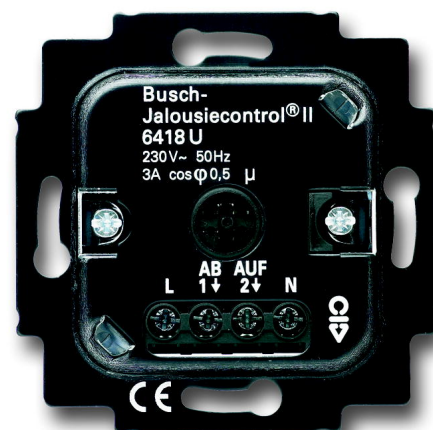

Suitable for blind and roller blind drives with mechanical or electronic limit switch shut-off.
Suitable for operation without neutral conductor.
Without an extension input.
For control cover 6430-xx-xxx.
For Standard timer control element 6456.
Running time: 3 min

Rated voltage: 230 V~, +10 % / -10 %, Rated frequency: 50 Hz,
Outputs: 2 Normally open contact, Rated current: 3 A, cos phi 0.5, Rated power: 690 VA
Temperature range (Device): 0 °C to 35 °C,
N-conductor connection required for operation with control cover 6430-7x, illuminated., N-conductor connection may be required for operation with blind and roller blind drives with electronic limit switch shut-off. If no N-conductor is available, capacitor set 6498 can be used.

Order Code : 6410-0-0376
Article No. : 6418 U-500
EAN: 4011395075760