

Cable trunking SES® with slots and base punching



GN-A6/4 LF




GN-A6/4 LF

Material:	Rigid PVC quality 9051 LF
Colour:	grey RAL7030
Operating temperatures:	-5 to +65°C
Density:	1,56
Volume resistivity:	10 ¹⁵ Ω.cm
Dielectric strength:	15kV/mm
Spécification:	V0 UL94 DIN 5510-2 S3, SR1, ST2
Standard length:	2 meters
Double sided adhesive:	upon request
Minimum delivery:	1 complete packing (with lids)



type	trunking art. no.		m	outside dim.		cables per trunking (filling 50 %)			lids (alone) art. no.		m
				H mm	W mm	1 mm²	1,5 mm²	2,5 mm²			
GN-A6/4 30 x 25	0839 0131	013	60	30	25	37	31	26	0839 0500	013	48
GN-A6/4 30 x 40	0839 0132	013	36	30	40	68	56	47	0839 0510	013	24
GN-A6/4 40 x 25	0839 0141	013	48	40	25	52	43	36	0839 0500	013	48
GN-A6/4 40 x 40	0839 0142	013	32	40	40	94	77	64	0839 0510	013	24
GN-A6/4 40 x 60	0839 0143	013	24	40	60	149	122	102	0839 0520	013	24
GN-A6/4 40 x 80	0839 0144	013	24	40	80	204	168	140	0839 0530	013	24
GN-A6/4 40 x 100	0839 0145	013	12	40	100	259	213	178	0839 0540	013	12
GN-A6/4 60 x 25	0839 0151	013	48	60	25	80	66	55	0839 0500	013	48
GN-A6/4 60 x 40	0839 0152	013	32	60	40	144	118	99	0839 0510	013	24
GN-A6/4 60 x 60	0839 0153	013	24	60	60	229	188	157	0839 0520	013	24
GN-A6/4 60 x 80	0839 0154	013	16	60	80	313	257	215	0839 0530	013	24
GN-A6/4 60 x 100	0839 0155	013	16	60	100	398	327	273	0839 0540	013	12
GN-A6/4 60 x 120	0839 0156	013	12	60	120	483	397	332	0839 0550	013	12
GN-A6/4 80 x 25	0839 0161	013	24	80	25	107	88	74	0839 0500	013	48
GN-A6/4 80 x 40	0839 0162	013	24	80	40	193	159	133	0839 0510	013	24
GN-A6/4 80 x 60	0839 0163	013	24	80	60	308	253	211	0839 0520	013	24
GN-A6/4 80 x 80	0839 0164	013	16	80	80	422	347	290	0839 0530	013	24
GN-A6/4 80 x 100	0839 0165	013	12	80	100	537	441	369	0839 0540	013	12
GN-A6/4 80 x 120	0839 0166	013	16	80	120	652	535	447	0839 0550	013	16
GN-A6/4 100 x 40	0839 0171	013	24	100	40	240	198	165	0839 0510	013	24
GN-A6/4 100 x 60	0839 0172	013	16	100	60	384	316	264	0839 0520	013	24
GN-A6/4 100 x 80	0839 0173	013	16	100	80	529	435	363	0839 0530	013	24
GN-A6/4 100 x 100	0839 0174	013	16	100	100	673	553	462	0839 0540	013	12

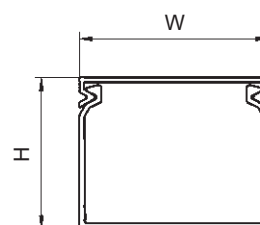

C3/1-01

C3/1-01

C3/1-02

C3/1-02

C3/5-01

C3/5-02




 



C3/6-01

C3/6-01


D4/6-01




GN-A6/4 LF

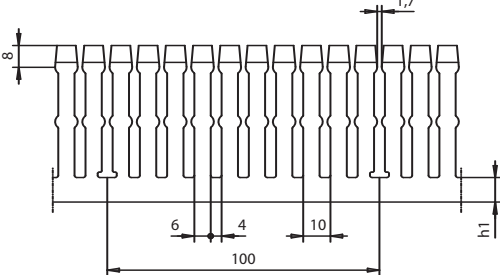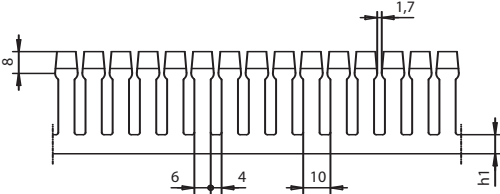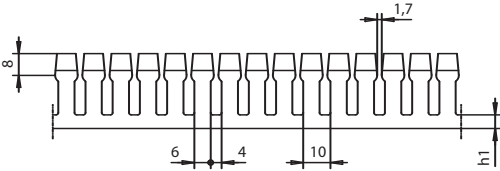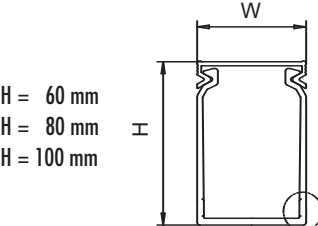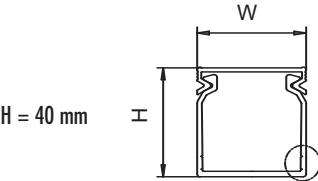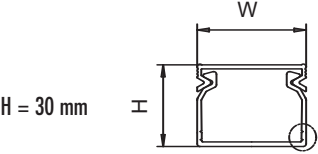

W = 25, 40 and 60 mm

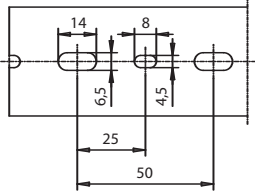

W = 80, 100 and 120 mm

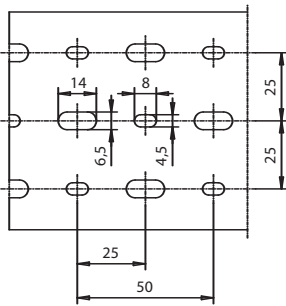

Base punching to NF EN 50085

H (mm)	30	40	60	80	100
h1 (mm)	5	7	9	11	16

