

## Datasheet

# RS 2 Core Multicore Speaker Cable, PVC Insulation 60 V

Stock number: 714-0304



### Product Description

#### Reference Standard

Customer's sample spec.and the general standard

#### Multi-construction

### Cable Construction


<b>Conductor</b>	<b>Bare Copper</b>
<b>Construction</b>	0.25±0.008×7
<b>Standard Dia.(mm)</b>	0.76
<b>Insulation</b>	<b>PVC</b>
<b>Thickness</b>	0.5
<b>Insulation Dia.(±0.1mm)</b>	1.8×2
<b>Insulation Color</b>	White
<b>Marking</b>	One Black Stripe on one leg of Twin

#### Print Marking

2 core 7/0.25mm 60 V PVC [MM][WkYr]

#### PACKAGING

100M/Cardboard Reel.

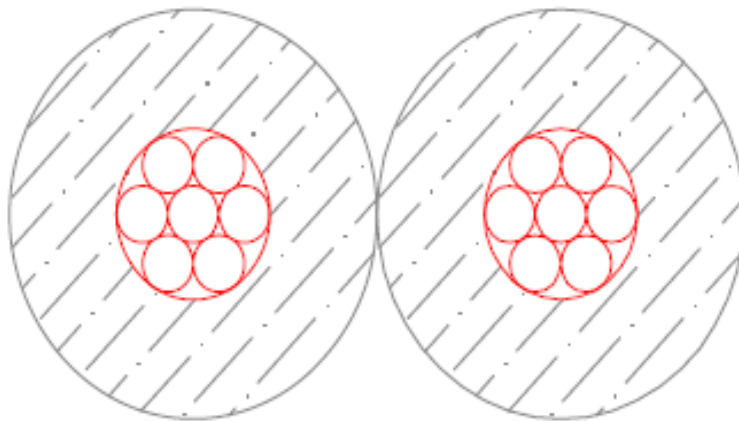

**Electrical Characteristics**

Max.Conductor DC Resistance at 20 °C ( $\Omega$ /Km)	<55.2
Min.Insulation DC Resistance at 20 °C (M $\Omega$ *Km)	200
Rated Temperature(°C)	80
Rated Voltage (V)	60