



Datasheet

Stock No: 712-5361

ENGLISH

RS Pro Blue Equipment Wire, 0.22mm² CSA, 1000 V 1.4 A 24 AWG, 500m



Product Description

Reference Standard

Customer's sample spec.and the general standard

Multi-construction

1

Cable Construction

Conductor

square(mm²)

Construction

Standard Dia.(mm)

Insulation

Thickness

Insulation Dia.(±0.1mm)

Insulation Color

Marking

According to the customer

Tinned Copper

0.22

T0.2±0.008×7


0.60

PVC

0.3

1.20

According to the custome

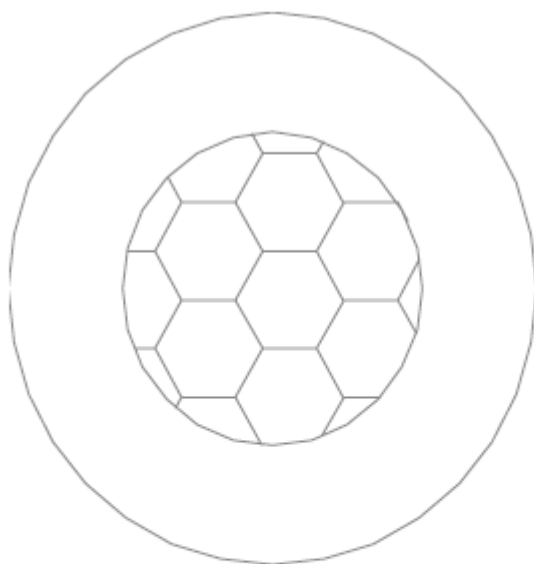

Electrical Characteristics

Max.Conductor DC Resistance at 20 °C (Ω /Km)	<86.2
Min.Insulation DC Resistance at 20 °C (M Ω *Km)	200
Rated Temperature(°C)	85
Rated Voltage (V)	1000