




Datenblatt - Fiche technique - Data sheet

RS Stock Number: 815-8567



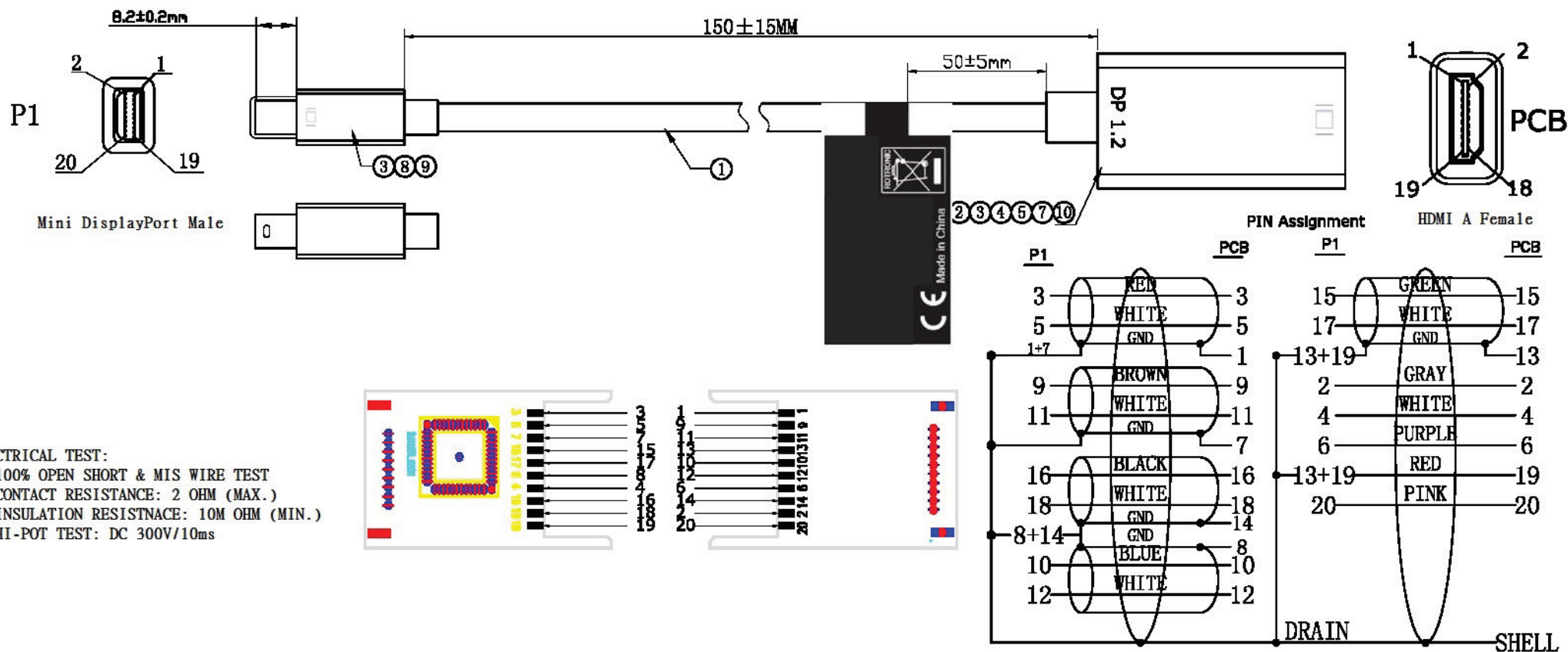

- ELECTRICAL TEST:**
- 100% OPEN SHORT & MIS WIRE TEST
 - CONTACT RESISTANCE: 2 OHM (MAX.)
 - INSULATION RESISTANCE: 10M OHM (MIN.)
 - HI-POT TEST: DC 300V/10ms



NO	DESCRIPTION	Q'TY	UNIT
10	W=20MM 25u DOUBLE CONDUCTIVE COPPER FOIL	0.09	m
9	Mini DP M(MiniDP/HDMI AF PCB) ABS One-piece WHITE	1	pcs
8	Mini DP M(MiniDP/HDMI AF PCB) ABS One-piece WHITE PRINT: [] (PT:COOL GRAY 8C W:5.0MM)	1	pcs
7	φ 0.8 heat shrinkable TUBE BLACK 6mm*5pcs	0.03	m
6	Mini DisplayPort M TRANSPARENT COLOR PVC DUST COVER	1	pcs
5	HDMI A F ABS One-piece HEADER Apple SNOWY WHITE	1	pcs
4	HDMI A F ABS One-piece SHELL WHITE PRINT: DP 1.2 (neutral)	1	pcs
3	65P SNOWY WHITE PVC	9	g
2	empty PCB + SMT + PLATED: NICKEL	1	pcs
1	Mini DP M to M PLATED: NICKEL SNOWY WHITE 34AWG AL 0.4M 5 Pair twist	1/2	pcs

TOLERANCE			DRAWN BY	Item No.:	815-8567
	INCHES	M/M			
.X	.015	.30			
.XX	.010	.10	Cable Adapter, Mini DP M to HDMI F white color, v1.2		
.XXX	.005	.05			
CHECK BY	SCALE	NONE	DRAWING NO.:	REV. A	
APPD BY	UNIT	MM			
	DATE	2014. 04. 01		1/3	