




## SOCKETS 1/4"

### A6800DZ

### DOUBLE HEXAGON LONG SERIES INCH

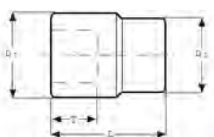

- Deep length sockets, 1/4" square drive
- Bi-hex profile, inch sizes
- Not suitable for machine operation
- High performance alloy steel
- High polished finish
- Knurled
- ISO 2725-1/1174-1
- DIN 3120
- Thin-walled
- These sockets are applicable to nuts and bolts used in the aerospace industry

|  | <br>731415 |  | <br>" | L<br>mm | D1<br>mm | D2<br>mm | T<br>mm | <br>g |
|-----------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------|----------------------------------------------------------------------------------------|---------|----------|----------|---------|------------------------------------------------------------------------------------------|
| A6800DZ-3/16                                                                      | 1758035                                                                                     | 1                                                                                 | 3/16                                                                                   | 50.6    | 7.7      | 12.1     | 5.1     | 21                                                                                       |
| A6800DZ-7/32                                                                      | 1758110                                                                                     | 1                                                                                 | 7/32                                                                                   | 50.6    | 8.5      | 12.1     | 5.3     | 21                                                                                       |
| A6800DZ-1/4                                                                       | 1758387                                                                                     | 1                                                                                 | 1/4                                                                                    | 50.6    | 9.3      | 12.1     | 5.8     | 23                                                                                       |
| A6800DZ-9/32                                                                      | 1758462                                                                                     | 1                                                                                 | 9/32                                                                                   | 50.6    | 10.5     | 12.1     | 6.6     | 21                                                                                       |
| A6800DZ-5/16                                                                      | 1758547                                                                                     | 1                                                                                 | 5/16                                                                                   | 50.6    | 11.5     | 12.1     | 8.1     | 23                                                                                       |
| A6800DZ-11/32                                                                     | 1803872                                                                                     | 1                                                                                 | 11/32                                                                                  | 50.6    | 12.6     | 12.1     | 8.1     | 25                                                                                       |
| A6800DZ-3/8                                                                       | 1758622                                                                                     | 1                                                                                 | 3/8                                                                                    | 50.6    | 14.1     | 12.1     | 8.1     | 28                                                                                       |
| A6800DZ-7/16                                                                      | 1803889                                                                                     | 1                                                                                 | 7/16                                                                                   | 50.6    | 15.4     | 13.0     | 11.2    | 30                                                                                       |
| A6800DZ-1/2                                                                       | 1758899                                                                                     | 1                                                                                 | 1/2                                                                                    | 50.6    | 17.5     | 15.0     | 12.7    | 41                                                                                       |
| A6800DZ-9/16                                                                      | 1758974                                                                                     | 1                                                                                 | 9/16                                                                                   | 50.6    | 18.8     | 16.0     | 12.7    | 49                                                                                       |