
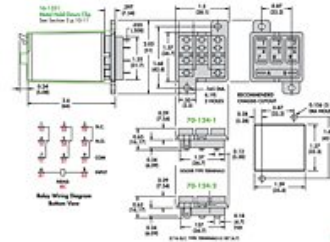


Item # 70-124-1, 70-124-1 Socket / 15 Amp Rating, 300 Volts

11 Pin, 0.130 Solder terminals with mounting tabs.

This Item is Normally Stocked

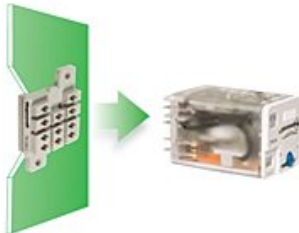

[Specifications](#) · [Electrical Rating](#) · [Temperature](#) · [Construction](#) · [Miscellaneous](#) · [Product Certifications](#)

Specifications

Check Inventory	Check Distributor Inventory
Contact Configuration	3PDT
Number of Terminals	11
Mounting Style	Panel Chassis

Electrical Rating

Current Rating	15 A
Nominal Voltage Rating	300 V

Temperature

Storage Range	- 40 to + 105 °C
---------------	------------------

Construction

Internal Metal Tracks	Copper Alloy Zinc Plated
Terminals	Copper Alloy Zinc Plated
Terminal Connection	Solder
Terminal Layout	Non-Logic
Base	Square

Miscellaneous

Wire Size Capacity (Maximum), EN 60204-1, Solid Cu	(Output): 16 AWG, 1.0 mm ₂
Wire Size Capacity (Maximum), EN 60204-1, Stranded Cu	(Output): 16 AWG, 1.0 mm ₂
Flammability Rating	94V-0 Class
Body Color	Light Gray

Product Certifications

Agency Approvals

CE
RoHS
UL
CSA