



Power and productivity
for a better world™

PRODUCT CARD

5.5.2012


AP9

Name: **Junction box IP65**
Surface-mounted junction box, IP65, 86 x 86 mm, white

Type: AP9
EAN: 6410016125095

Description: The square junction box AP9 (2,5 mm², 500 V) is equipped with 10 membrane cable entries (Ø 17 mm) in the sides, and two at the bottom. Cables are easy to connect by simply inserting the stripped ends through the inlets. The box locks by snapping and can be opened by inserting a screwdriver (for example) into the opening slots - no screws are needed. The box can be furnished with strain-reliefs AS9, AS9.1 and AS9.3. Fits Ø 6 - 15,5 mm cable. VDE-approved. Mounting temperature -15...+60 °C.

Package: 5/50
Unit: PCS

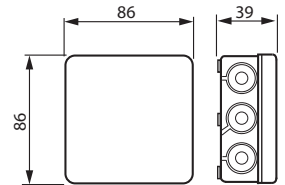

Technical specification

Colour: Hvit
Dimensions (mm): 86 x 86 x 39 mm
Enclosure class: IP 65
Operating temperature (°C): -15...+60
Rated voltage (V): 500
Weight (g/each): 56

Address
P.O. Box 16
06101 Porvoo
FINLAND

ABB Exchange
+358 10 22 11

Customer service
customerservice.ABJ@fi.abb.com

Web
<http://www.abb.fi>

Business ID
0763403-0