

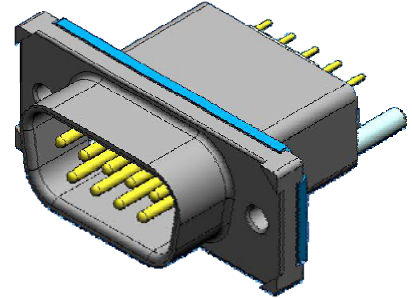


Industrial/Military Harsh Environment D-subminiature Connectors

IP67

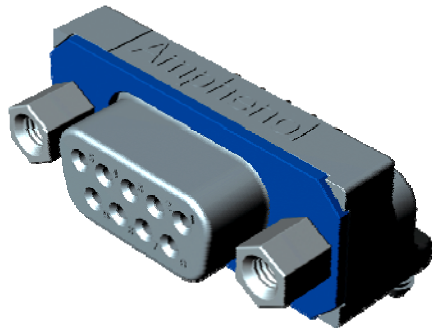

Cost efficient environmentally sealed D-Subminiature connectors with screw machine contacts and high performance thermoplastic or metal die cast shells.

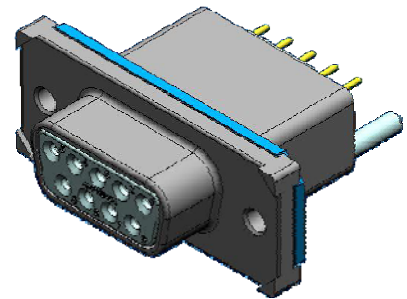

Specification:

Working Voltage:	200 VDC, 125VAC
Dielectric Withstanding Voltage (@25°C & 50 mA max. charging current)	500 VDC
Minimum Insulation Resistance (@25°C & working voltage)	10 Gohms
Contact current rating (continuous max, DC)	5 Amperes
Continuous operating temperature	-40°C to +125°C

Materials & Finishes:

Contacts:	Copper alloy gold over nickel plate
Gasket:	Silicone rubber
Insulator:	High temperature thermoplastic
Compliance:	RoHS