

PRODUCT CODE

AHG45W

PRODUCT TITLE

45 Element High Gain TV Aerial



FEATURES


Sealed "F" connector dipole housing
2 piece boom for compact packaging
Centre or end mounting options
Large reflector for good F/B ratio
Galvanised Heavy Duty Tilt Clamp
Robust 18mm boom construction
Quick assembly and set up
Ideal for weak reception areas
Light grey plastics to lessen visual impact

PRODUCT SPECIFICATION

Group: Wideband
Forward Gain: 13dB(d)/15.15 dB(i)
Front to Back Ratio: >20dB
Acceptance Angle: $\pm 17.5^\circ$
Channel Number: 21-69
Frequency Range: 470-862MHz
Elements: 45
Assembled Length: 1320mm
Benchmark Standard: 2

PACKAGING DETAILS

Packaging Style: Packed 5 per box. Individually poly bagged
Packaging Dimensions: W:460mm x H:840mm x D:75mm
Barcode Number: 5016163521295
Product Weight: 1.7kg (per product)
Packaging Weight: 89g (per poly bag)

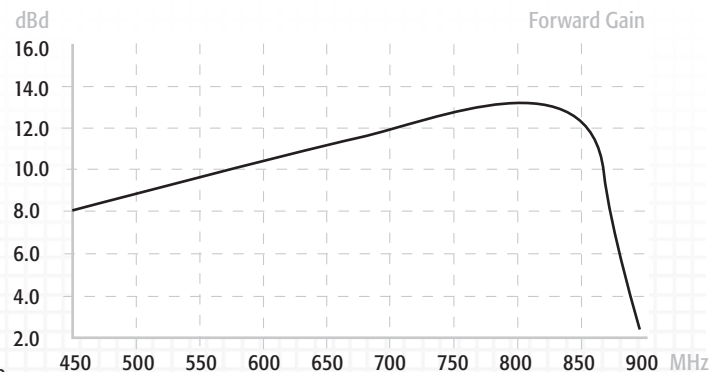

Maxview Ltd, Common Lane, Setchey, King's Lynn, Norfolk, PE33 0AT.
■ Sales Line: 01553 813333 ■ Fax: 01553 813320 ■ Helpline: 01553 811000

Maxview reserve the right to change specifications without prior notice