



S. Lilley & Son Limited



LAMPHOLDERS

LIGHTING COMPONENTS

PRESSINGS

TURNED PARTS

LED LIGHTING

2014-2015



S Lilley & Son was founded circa 1840 by Simeon Lilley (top centre) to produce components for the then expanding railway industry. As the years progressed into the early 20th century, the portfolio of products steadily expanded to include the motor, cycle, furniture and electrical trades.

During this period one of the directors could see potential in the then new radio transmission services. Consequently we were one of the first manufacturers of a commercially available crystal set, 'The Imperial'. The introduction of electric lighting saw 'Lilley's' as one of a number of Birmingham based manufacturers who started to produce brass lampholders. This part of the business has continued to this day and we are now the leading UK manufacturer of specialized lighting components.

The Black and White pictures above give a brief pictorial history of the company from the early 20's.



FM 20640



CONDITIONS OF SALE

Orders

Orders accepted and acknowledged by us cannot be cancelled without our consent. They are accepted for delivery without responsibility for unforeseen hindrances, shortage of materials, delays in transit or accident, etc. Any promise of delivery is given in good faith, but cannot be guaranteed. Quoted delivery time will be adhered to as far as is possible, but no responsibility can be accepted for delays caused by industrial disputes or disruption by any third party outside our control.

Contracts

Delivery of contract must be taken within the period specified, otherwise we reserve the right to cancel or deliver the outstanding balance at the end of the contract period.

Acceptance of Orders

Orders and contracts are only accepted in accordance with our conditions of sale. Unless expressly accepted in writing, any deviation from these conditions in a customer's 'order conditions of purchase' will be deemed to be and treated as inapplicable.

Part Deliveries

Where goods are contracted for delivery by installments, each delivery will constitute a separate enforceable order.

Prices

Every effort will be made to carry out any contract in accordance with the quoted price. We do however, reserve the right to amend any quotation either before or after acceptance, should manufacturing cost necessitate such an amendment.

Carriage

Carriage is paid on consignments of £250 net value and over for delivery throughout England, Wales and Southern Scotland. For all other areas, prices quoted are ex-works.

Minimum Invoice Value

A minimum invoice value of £25.00 is applied to all orders.

Notification of Loss or Damage

For all consignments dispatched for delivery on the UK mainland, in the event of damage, partial loss or non-delivery of goods, the Buyer or their Agents must notify the Seller within three working days of dispatch. For all other areas notifications must be made within 7 working days.

Settlement Terms

All accounts are strictly net monthly and are due on the last day of the month following that of delivery. All clerical errors and omissions will be subject to correction.

New Accounts

All new accounts will operate on a Pro-Forma basis. Credit accounts will be opened subject to approval by third party credit agency checks.

Risk and Title

The risk in the goods shall pass to the Buyer on delivery, but the legal title in the goods shall remain with the Seller, until payment is received in full for the goods. Until title to the goods has passed to the Buyer, the Buyer shall hold the goods as bailee for the Seller and shall deliver up the goods to the Seller on his order or demand.

Quality

The quality of its products is of paramount importance to the company. All materials and manufacturing processes are strictly monitored in accordance with its BS EN ISO 9001 Quality Control Procedures registration FM20640, to ensure the use of good quality materials and to monitor all stages of production. However, any products that are found to be faulty will either be replaced free of charge or a credit given, provided such products are returned within three months of delivery. Under no circumstances can we accept responsibility for any costs that are involved, either direct or consequential, resulting from faulty products.

TRANSFER PRESSINGS




S Lilley & Son are specialists in deep drawn pressings operating Platarg Transfer presses. These machines are the ideal solution where higher volumes are required. They enable close tolerances to be maintained over long production runs with a low unit cost. Because of the multistage configuration, tooling packages are simpler and therefore of a lower cost than conventional presswork methods.

We utilise Platarg presses of 3,4 and 6 ton per stage.



CONVENTIONAL PRESS WORK

We utilise conventional 'C' frame presses from 10 tonnes up to 90 tonnes capacity. This gives us great flexibility in the presswork services we can offer. We provide full second operation capacity for the more complex fabrications.

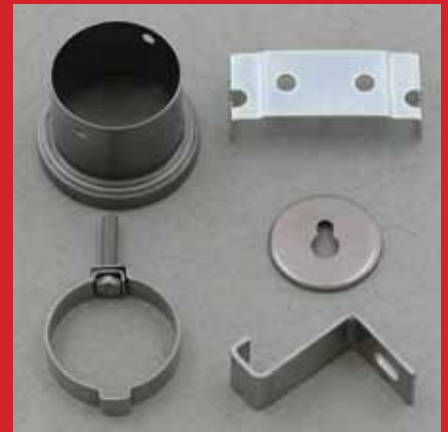

We offer services for turned parts of up to 2" diameter on single spindle automatics and CNC bar turning for more complex components of up to 35mm diameter.



CERTIFICATION

All the latest certification available for Lilley products and factored items is available as PDF downloads from our website:
www.s-lilley.co.uk



We are agents for Framon, Italian manufacturers of a vast range of high quality decorative cast brass lighting components.

A CD Rom catalogue is available on request or visit www.framon.it



B22 BAYONET CAP LAMPHOLDERS



3003E

3004E

1003E



3119E



3005E



1117EN



3003EZ



3000E



1005EC



1035E



3009E



1037E



9060E



3011E



9060



5030



3110



BC7



3015E



BC8

THREADED ENTRY LAMPHOLDER WITH SHADE RING

Cat No	Thread Size	Max Ht	Max Dia
1003E	M10 X 1mm pitch threaded entry	44.7mm	32mm
1005E	M13 X 1mm pitch threaded entry	44.7mm	32mm
1035E	M20 X 1.5mm pitch threaded entry	45.6mm	32mm
1037E	M16 X 1.5mm pitch threaded entry	45.6mm	32mm
3001E	3/8" X 26 tpi threaded entry	44.7mm	32mm
3003E	1/2" X 26 tpi threaded entry	44.7mm	32mm
3005E	5/8" X 26 tpi threaded entry	44.2mm	32mm
3033E	3/8" BSP threaded entry	45.0mm	32mm
3035E	3/4" Conduit threaded entry	45.0mm	32mm
3037E	5/8" Conduit threaded entry	45.0mm	32mm
3117E	5/8" X 26 tpi external thread	45.0mm	32mm

THREADED ENTRY LAMPHOLDER PLAIN (WITHOUT SHADE RING)

Cat No	Thread Size	Max Ht	Max Dia
1004E	M10 X 1mm pitch threaded entry	44.7mm	32mm
1006E	M13 X 1mm pitch threaded entry	44.7mm	32mm
1036E	M20 X 1.5mm pitch threaded entry	45.6mm	32mm
1038E	M16 X 1.5mm pitch threaded entry	45.6mm	32mm
3002E	3/8" X 26 tpi threaded entry	44.7mm	32mm
3004E	1/2" X 26 tpi threaded entry	44.7mm	32mm
3006E	5/8" X 26 tpi threaded entry	44.2mm	32mm
3034E	3/8" BSP threaded entry	45.0mm	32mm
3036E	3/4" Conduit threaded entry	45.0mm	32mm
3038E	5/8" Conduit threaded entry	45.0mm	32mm
3116E	5/8" X 26 tpi external thread	45.0mm	32mm

TWO PIECE CANDLE LAMPHOLDER

Cat No	Thread Size	Max Ht	Max Dia
9060	M10 X 1mm pitch threaded entry no earth	41.6mm	24.2mm
9060E	M10 X 1mm pitch threaded entry	41.6mm	24.2mm

INTERNAL LOCKING LAMPHOLDER WITH SHADE RING

Cat No	Thread Size	Max Ht	Max Dia
1117E	M10 X 1mm pitch threaded entry	48mm	32mm
1119E	M13 X 1mm pitch threaded entry	48mm	32mm
3119E	1/2" X 26 tpi threaded entry	48mm	32mm

INTERNAL LOCKING LAMPHOLDER PLAIN (WITHOUT SHADE RING)

Cat No	Thread Size	Max Ht	Max Dia
1118E	M10 X 1mm pitch threaded entry	48mm	32mm
1120E	M13 X 1mm pitch threaded entry	48mm	32mm
3118E	1/2" X 26 tpi threaded entry	48mm	32mm

PENDANT LAMPHOLDER WITH SHADE RING

Cat No	Thread Size	Max Ht	Max Dia
3000E	Integral cord grip	58mm	32mm

OPEN BACK & SIGN TYPE LAMPHOLDERS

Cat No	Type	Max Ht	Max Dia
3007	Open back with shade ring no earth	35mm	32mm
3120E	Sign type plain	40.5mm	32mm
3121E	Sign type with shade ring	40.5mm	32mm

BATTEN LAMPHOLDER WITH SHADE RING

Cat No	Type	Max Ht	Max Dia
3009E	40mm PCD 3 Hole fixing	38.2mm	51.7mm
3011E	50mm 2 Hole BESA fixing	39.0mm	68.6mm
3015E	40mm 2 Hole 45° angle fixing	48.0mm	48.0mm
3111	42mm 2 Hole fixing no earth	37.5mm	51.0mm

BATTEN LAMPHOLDER PLAIN (WITHOUT SHADE RING)

Cat No	Type	Max Ht	Max Dia
3010E	40mm PCD 3 Hole fixing	38.2mm	51.7mm
3012E	50mm 2 Hole BESA fixing	39.0mm	68.6mm
3016E	40mm 2 Hole 45° angle fixing	48.0mm	48.0mm
3110	42mm 2 Hole fixing no earth	37.5mm	51.0mm
5030	39.5mm Porcelain 2 slot	36.5mm	58.0mm

EXTRAS

Suffix 'A'	Brushed antique finish
Suffix 'E'	Fitted with earth terminal
Suffix 'C'	Chrome plated finish
Suffix 'Z'	Bronze finish
Suffix 'N'	Nickel plated finish
Suffix '3BS'	Three slot bayonet caps

STANDARD PACKS OF 10 OR UNASSEMBLED IN BULK PACKS

B22 SWITCHED LAMPHOLDERS



3413EH

1413EN

3413EC



1413E

3413EZ

1413EA



BC9

BC10



BC3

BC1

BC5



1423E

1423E

3423EZ

PUSHBAR SWITCHED LAMPHOLDER

Continual improvements in design ensure that 'Lilley' products are in the forefront of Quality, Safety and Reliability. The redesigned switched lampholder now has the earth terminal incorporated into the interior moulding making wiring more efficient and removing the unsightly earth terminal from the exterior of the lampholder. It still retains the virtues of the thicker brass case for strength, large finger switch pads for comfortable operation and extended interior nose for rigidity. The interior is available with both screw terminals and screwless 'push in' terminals for increased speed of wiring. The screwless terminal lampholders accept prepared leads with 8mm to 10mm tinned ends.

THE SAFER-SWITCHED ENHANCED SAFETY LAMPHOLDERS

This product offers the consumer an extra level of safety previously unavailable in this type of lampholder. A simple yet reliable patented innovation ensures that the switch returns and remains in the off position whenever the bulb is removed. This represents a significant advance in luminaire safety and is fully certified to BS7895:1997 Enhanced Safety Lampholder standard.

STANDARD PACKS OF TEN.

THREADED ENTRY SAFER-SWITCHED LAMPHOLDERS

Cat No	Thread Size	Max Ht	Max Dia
1413E	M10 x 1mm pitch threaded entry	61mm	32mm
1414E	M13 x 1mm pitch threaded entry	61mm	32mm
3413E	½" x 26tpi threaded entry	61mm	32mm

SCREWLESS TERMINAL SAFER-SWITCHED LAMPHOLDERS

Cat No	Thread Size	Max Ht	Max Dia
1413P	M10 x 1mm pitch threaded entry	61mm	32mm
3413P	½" x 26tpi threaded entry	61mm	32mm
1414P	M13 x 1mm pitch threaded entry	61mm	32mm

INTERNAL LOCKING SAFER-SWITCHED LAMPHOLDERS

Cat No	Thread Size	Max Ht	Max Dia
1423E	M10 x 1mm pitch threaded entry	61mm	32mm
1424E	M13 x 1mm pitch threaded entry	61mm	32mm
3423E	½" x 26tpi threaded entry	61mm	32mm

THREADED ENTRY SWITCHED LAMPHOLDERS

Cat No	Thread Size	Max Ht	Max Dia
1013E	M10 x 1mm pitch threaded entry	61mm	32mm
1014E	M13 x 1mm pitch threaded entry	61mm	32mm
3013E	½" x 26tpi threaded entry	61mm	32mm

SCREWLESS TERMINAL SWITCHED LAMPHOLDERS

Cat No	Thread Size	Max Ht	Max Dia
1013P	M10 x 1mm pitch threaded entry	61mm	32mm
1014P	M13 x 1mm pitch threaded entry	61mm	32mm
3013P	M13 x 1mm pitch threaded entry	61mm	32mm

INTERNAL LOCKING SWITCHED LAMPHOLDERS

Cat No	Thread Size	Max Ht	Max Dia
1113E	M10 x 1mm pitch threaded entry	61mm	32mm
1114E	M13 x 1mm pitch threaded entry	61mm	32mm
3113E	½" x 26tpi threaded entry	61mm	32mm

COMPONENT PARTS FOR ALL BC LAMPHOLDERS

Cat No	Description	Cat No	Description
BC1	Threaded Bayonet Cap	BC7	Large Base Interior
BC2	Plain Bayonet Cap	BC8	Small Base Interior
BC3	Standard Union Ring	BC9	Switched Interior
BC4	Heavy Union Ring	BC10	Safer Switched Interior
BC5	Standard Shade Ring	BC29	Switched Pushfit interior
BC6	Heavy Shade Ring	BC30	Safer Switched Pushfit interior

EXTRAS

Suffix 'A'	Brushed Antique Finish
Suffix 'E'	Fitted Earth Terminal
Suffix 'C'	Chrome Plated Finish
Suffix 'H'	Old English Brass Finish
Suffix 'Z'	Bronze Finish
Suffix 'N'	Nickel Plated Finish
Suffix '3BS'	Three Bayonet Slot Caps

B15 SBC, LOW VOLTAGE & HALOGEN LAMP HOLDERS



THREADED ENTRY LAMP HOLDERS

Cat No	Thread Size	Max Dia	Max Ht.
1021E	M10 X 1mm pitch with shade ring	23.2mm	38.7mm
1022E	M10 X 1mm pitch plain (no shade ring)	23.2mm	38.7mm
3021E	3/8" X 26 tpi with shade ring	23.2mm	38.7mm
3022E	3/8" X 26 tpi plain (no shade ring)	23.2mm	38.7mm
3023E	1/2" X 26 tpi with shade ring	23.2mm	38.7mm
3024E	1/2" X 26 tpi plain (no shade ring)	23.2mm	38.7mm

PENDANT & OPEN BACK LAMP HOLDERS

Cat No.	Type	Max Dia	Max Ht.
3020E	Pendant cord grip with shade ring	23.2mm	47.0mm
3025	Open back with shade ring	23.2mm	30.5mm

CANDLE TYPE LAMP HOLDERS (NO EARTH TERMINAL)

Cat No.	Thread size	Max Dia	Max Ht.
1018	M10 X 1mm pitch plain barrel	21.0mm	40.0mm
3018A	1/2" X 26 tpi plain barrel	21.0mm	40.0mm

BATTEN FIXING LAMP HOLDERS

Cat No.	Fixing	Fixing Centre	Max Dia	Max Ht.
3027E	3 Hole with shade ring	30mm PCD	38mm	32.2mm
3028E	3 Hole plain (no shade ring)	30mm PCD	38mm	32.2mm
3028	3 Hole plain (no shade ring)	30mm PCD	38mm	32.2mm
3031	2 Hole with shade ring	31mm	36.3mm	34mm
3032	2 Hole plain (no shade ring)	31mm	36.3mm	34mm

COMPONENT PARTS

SBC1	Threaded bayonet cap
SBC5	Shade ring
SBC2	Plain bayonet cap
SBC6	Double contact S interior
SBC3	Standard union ring
SBC7	Single contact 12v interior 5amp
SBC4	Batten union ring
SBC10	B15 double contact 12v interior 10amp
BAY15D	Offset J slot bayonet cap

Suffix 'E'	Fitted with earth terminal
Suffix 'C'	Chrome plated finish
Suffix 'Z'	Bronze finish
Suffix 'N'	Nickel plated finish
Suffix 'A'	Brushed Antique finish

B15S (SCC)

All SBC lamp holders can be supplied with a single centre contact interior, SBC7. 12volt 5amp. Please add suffix 'CC' to catalogue number.

B15D LOW VOLTAGE HALOGEN

3521	B15D 10mm Brass Shade ring lampholder 12volt 10amp
3522	B15D 10mm Brass Plain lampholder 12volt 10amp
3523	B15D 1/2" Brass Shade ring lampholder 12volt 10amp
3524	B15D 1/2" Brass Plain lampholder 12volt 10amp

HALOGEN LAMP HOLDERS

5040	G9 lampholder 28mm dia body
5040B	10mm fixing snap fit body 28mm dia
5040T	Shade ring 28mm dia
5042	G9 lampholder 21mm dia body
5042B	10mm fixing snap fit body 21mm dia
5042T	Shade ring 21mm dia
5342	Brass G9 plain cup 25mm OD x 25mm high
5039	GZ10 ceramic lampholder
5039B	10mm fixing snap fit body GZ10
5023/15S	G4 - GY6.35 lampholder with 150mm Silicone leads

EDISON SCREW LAMPHOLDERS

EDISON SCREW LAMPHOLDERS

This range of High Quality Brass Body Edison Screw lampholders will enhance any Luminaire greatly increasing its perceived value.

They are available in a variety of finishes.

E27 (ES) LAMPHOLDERS PLAIN (NO SHADE RING)

Cat No.	Fixing	Max Dia	Max Ht.	Old Cat No
7600E	Pendant Cord Grip	39mm	68mm	4000E
7601E	M10 x 1mm pitch	39mm	60mm	7011E
7602E	½" x 26tpi	39mm	60mm	4002E
7603E	M13 x 1mm pitch	39mm	60mm	7013E
7604E	5/8" x 26tpi	39mm	60mm	4003E
7605E	M16 x 1.5 pitch	39mm	60mm	7004E
7606E	M20 x 1.5 pitch	39mm	60mm	7006E
7607E	2" centre Batten Fixing	67mm	54mm	4007E
7608E	Open back	39mm	52mm	
7609E	3/8" BSP	39mm	60mm	

E27 (ES) LAMPHOLDERS WITH SHADE RING

Cat No.	Fixing	Max Dia	Max Ht	Old Cat No
7600ET	Pendant Cord Grip	48mm	68mm	4009E
7601ET	M10 x 1mm pitch	48mm	60mm	7010E
7602ET	½" x 26tpi	48mm	60mm	4010E
7603ET	M13 x 1mm pitch	48mm	60mm	7012E
7604ET	5/8" x 26tpi	48mm	60mm	4011E
7605ET	M16 x 1.5 pitch	48mm	60mm	7003E
7606ET	M20 x 1.5 pitch	48mm	60mm	7005E
7607ET	2" centre Batten Fixing	67mm	54mm	4014E
7608ET	Open back	48mm	52mm	

CERAMIC LAMPHOLDERS

Cat No.	Fixing	Max Dia.	Max Ht.
5022	2 slot 48mm ctrs. Ceramic Body E27	59mm	47mm
9042	Back Fix 57mm ctrs Ceramic body E40	70mm	80mm

E14 (SES) LAMPHOLDERS (Plated Steel Case)

Cat No.	Fixing	Max Dia	Max Ht
9050E	M10 x 1mm pitch Plain Brass Plated	28mm	53mm
9050EN	M10 x 1mm pitch Plain Nickel Plated	28mm	53mm
9051E	M10 x 1mm pitch Shade Ring Brass Plated	42.5mm	53mm
9051EN	M10 x 1mm pitch Shade Ring Nickel Plated	42.5mm	53mm

E27 PLASTIC LAMPHOLDERS

Cat No.	Fixing	Max Dia	Max Ht
9801	M10 BLACK PLASTIC 2 SHADE RINGS	47mm	54mm

SPARES

Cat No.	Fixing	Max Dia
ES1	Brass Shade Ring E27	48mm Dia.
4057	Steel 18g ES flange washer	57mm Dia

IMPORTANT NOTE

EDISON SCREW LAMPHOLDER OUTER CASES ARE CONSTRUCTED TO LOCK TOGETHER WHEN FULLY ASSEMBLED AND TIGHTENED. TO RELEASE, INSERT A SCREWDRIVER BETWEEN THE OUTSIDE TONGUE OF THE CENTRE CONTACT AND THE PLASTIC LINER AND LEVER IN.

Extras

Suffix 'A'	Brushed Antique Finish
Suffix 'E'	Fitted Earth Terminal
Suffix 'C'	Chrome Plated Finish
Suffix 'H'	Old English Brass Finish
Suffix 'Z'	Bronze Finish
Suffix 'N'	Nickel Plated Finish

PACKED IN BOXES OF TEN



7601EN



7607ET



7602E



7600ET



7601ETH



7603ETC



7600EZ



ES1



7609E



7601E



5022



7606E



9801



ES4



9042



9050EN



9051EN



9051E



9050E

AMERICAN WIRING PRODUCTS



AMERICAN WIRING PRODUCTS

This selection of US wiring accessories are all either UL Listed or Recognised components, suitable for both the USA and Canada. They are all of the highest quality and will ensure you can confidently supply first class luminaires into North America.

E26 Edison Screw Lampholders Snap Fix UL File No. E213715

		Max Dia	Max Height
22003	10mm Unswitched	1.380"	2.15"
22003N	10mm Unswitched Nickel	1.380"	2.15"
22013	10mm Switched push bar	1.380"	2.50"
22043	10mm 3way Switch turn key	1.380"	2.50"

E26 Edison Screw Brass Heavy Body Lampholders UL File No. E227063

9323	10mm Pull Chain	1.50"	2.80"
9343	10mm 3 way Switch turn key	1.50"	2.80"
9323T	10mm Pull Chain Uno Thread (33mm dia) for shade ring	1.50"	2.80"
9333T	10mm Unswitched Uno thread for shade ring	1.50"	2.30"
9343T	10mm 3 way Switch turn key Uno thread for shade ring	1.50"	2.80"
7900	40mm Shade Adapter for Uno thread lampholders (suffix T)		
ES1	ES Brass Shade ring (fits above adapter)		

Phenolic E12 Lampholders

9701	10mm entry Candelabra UL file no E86201	1.125"	1.625"
9705	E12 Shade Ring for above.		
9703	1/8" IP Extended Candelabra UL file no E136279	0.80"	2.10"

Detachable Harps Complete with Base

19065	6.1/2" Brass Plated
19066	7" Brass plated
19068	8" Brass plated
19070	9" Brass plated
19072	10" Brass plated
19074	11" Brass plated
19076	12" Brass Plated
19078	13" Brass Plated

Detachable Harp Base

28250	Base plate brass plated
-------	-------------------------

Harp Finials

7020	1/4" x 27 tpi Brass ball
7021	1/4" x 27 tpi Brass ornamental

US Thread Accessories

7025	1/8" IP Brass lock nut
7030	10mm x 1/4" 27tpi Headless reducer
7031	1/2" x 1/8" IP Knurled head reducer

UL Plug Leads UL File No. E87333

ULPL30B	3m SPT2 Polarized UL Black Plug Lead
ULPL30G	3m SPT2 Polarized UL Gold Plug Lead
SCULB25P	2.5m SPT2 Polarized UL Switched Black Plug lead

FLEXIBLE CABLE



FLEXIBLE CABLE

Flex

9990W	White 2183Y 0.5 3 core flex 100m rolls
9980G	Gold 2183Y 0.5 3 core flex 100m rolls
9980B	Black 2183Y 0.5 3 core flex 100m rolls
9991W	White 2183Y 0.75 3 core flex 100m rolls
9981G	Gold 2183Y 0.75 3 core flex 100m rolls
9981B	Black 2183Y 0.75 3 core flex 100m rolls
2491X	Multistrand 0.5 mm 100m rolls red or black
UY2	Mini waterproof connectors push to connect

ACCESSORIES



THREADS ARE 26TPI OR 1MM PITCH UNLESS OTHERWISE STATED

M = Male thread F = Female thread

Plain Brass Ring Nuts

3073	5/16" x 1/2" OD x 1/8" thick
3074	1/2" x 5/8" OD x 1/8" thick
3075	3/8" x 1/2" OD x 1/8" thick
7073	M8 x 1/2" OD x 3.3mm thick
7074	M10 x 20mm OD Dome ring nut
7075	M10 x 1/2" OD x 3.3mm thick
7076	M13 x 5/8" OD x 3.3mm thick
7077	5/8" x 3/4" OD x 1/8" thick
7079	1/2" x 7/8" OD x 3.4mm thick

Hexagon Locknuts

3050	1/2" x 5/8" AF x 1/8" thick brass
3051	3/8" x 1/2" AF x 1/8" thick brass
3052	5/8" x 13/16" AF x 1/8" thick brass
3057	5/16" IP x 1/2" AF x 1/8" thick brass
7025	1/8" IP x 1/2" AF x 1/8" thick brass
7050	M8 x 1/2" AF x 3.3mm thick brass
7051	M10 x 1/2" AF x 3.3mm thick brass
7051S	M10 x 1/2" AF x 3.5mm thick steel ZP
7052	M13 x 5/8" AF x 3.3mm thick brass

Reduction Bushes

3046	1/2" M to 3/8" F knurled head brass
3047	5/8" M to 1/2" F knurled head brass
3076R	1/2" F to M10 F ornamental brass
3077	1/2" M to M10 F headless brass
3080	1/2" M to M10 F hexagon head brass
3088	1/2" F to M10 F bobbin brass
3096	1/2" M to M10 F knurled head brass
3097	1/2" M to 5/16" F knurled head brass
3196	3/8" BSP M to M10 F plain head brass
7030	M10 M to 1/4" 27tpi F knurled head brass
7031	1/2" M x 1/8" IP F knurled head brass
7046	M13 M x M10 F knurled head brass
7047	M13 M x M10 M connector brass
7057	M10 M x M8 F plain head brass
7090	M13 F x M10 M plain brass

Couplers

3055	3/8" x 1/2" OD x 3/4" long plain brass
3058	1/2" x 9/16" OD x 3/4" long plain brass
3076	1/2" x 11/16" OD x 1/2" long ornamental brass
3086	M10 x 11/16" OD x 1/2" long ornamental brass
7055	M10 x 1/2" OD x 3/4" long plain brass
7055EM	M10 x 1/2" OD x 3/4" long 10mm milled end
7056	M10 x 1/2" OD x 12mm long plain brass
7058	M13 x 5/8" OD x 3/4" long plain brass
7059	M13 x 5/8" OD x 40mm long plain brass
7155	M10 x 1/2" OD x 40mm long plain brass
9212	M10 x 17mm OD x 19mm long slotted brass Hickey
9212S	M10 x 21mm long steel Hickey

Wood Pillar Nipples

3045	1/2" M x 7/16" whit M x 3/4" long brass
3045S	1/2" M x 7/16" whit M x 1/2" long brass
7045	M10 M x 3/8" whit M x 3/4" long brass

Pottery Nipples

3092	1/2" x 1/2" long x 5/8" dia round head brass
7091	M10 x 9mm long x 1/2" AF hex head brass
7092	M10 x 15mm long x 1/2" AF hex head brass
9092	1/2" x 5/8" long x 12mm AF hex head plastic

Back Plates

3048	1/2" M x 1" dia 3 hole fix brass
7048	M10 M x 1" dia 3 hole fix brass
7049	M13 M x 1" dia 3 hole fix brass
CSK	Add this suffix for countersunk holes

Rivetting Pummels

3094	1/2" M thread brass
3095	1/2" F thread brass
7095	M10 F thread brass
7096	M10 M thread brass

End Cap Nuts - Finials

2014	1/2" x 5/8" OD x 1/2" long plain brass
3093	1/2" x 3/4" OD x 9/16" long ornamental brass
7015	M10 x 7/8" OD x 1.1/4" long rope edge brass
7016	M10 x 3/4" OD x 9/16" long ringed brass
7017	M10 x 7/8" OD x 1.3/8" long crown finial brass
7020	1/4" 27tpi x 7/8" OD x 1.3/8" long harp finial brass
7024	M10 x 5/8" OD x 7/8" long globe finial brass
7093	M10 x 3/4" OD x 9/16" long ornamental brass
7097	1/2" x 1" OD x 1.1/8" long ball finial brass
7098	M10 x 7/16" OD x 1.1/8" long regency finial brass
7112	M10 x 5/8" OD ball brass
7113	M10 x 1/2" OD plain cap brass
7114	M10 x 5/8" OD x 5/16" long button finial brass
7115	M5 x 10mm OD ball brass

ACCESSORIES

ALL THREADS



TUBE SPACERS

7165



SPE023 SPE024 7166 7065 7068C



7066D 7066C 7067C 7069A 7068A 7069F



2010 2002 2000 2060 2006

Brass Allthread Nipples

3237	1/2" x 3" long	7134	M10 x 75mm long
3238	1/2" x 2.1/2" long	7135	M10 x 63mm long
3239	1/2" x 2" long	7136	M10 x 50mm long
3240	1/2" x 1.1/2" long	7137	M10 x 38mm long
3241	1/2" x 1.1/4" long	7138	M10 x 32mm long
3042	1/2" x 1" long	7039	M10 x 25mm long
3043	1/2" x 3/4" long	7040	M10 x 19mm long
3044	1/2" x 1/2" long	7041	M10 x 13mm long
7042	M13 x 25mm long		
7043	M13 x 19mm long		
7044	M13 x 13mm long		

Steel Allthread Nipples

9030	M10 x 1 metre long
9031	1/2" x 1 metre long

Brass Barrel Polished Tube Spacers

7100	1/2" long 1/2" OD X 10mm Clear bore
7101	1" long 1/2" OD X 10mm Clear bore
7102	1.1/2" long 1/2" OD X 10mm Clear bore
7103	2" long 1/2" OD X 10mm Clear bore
7104	3" long 1/2" OD X 10mm Clear bore
7105	1.1/4" long 1/2" OD X 10mm Clear bore
7106	3/4" long 1/2" OD X 10mm Clear bore
7107	2.1/2" long 1/2" OD X 10mm Clear bore
7108	1" long 5/8" OD X 1/2" Clear bore

Suffix PL - Supplied hand polished and lacquered
 Suffix R - Reeded pattern tube

Brass Centre Mounts

7065	1/2" male thread 45' twin arm cone mount
7066A	1/2" tapped x 1/2" side drilled 19mm OD mount
7066C	1/2" tapped x M10 side tapped 19mm OD mount
7066D	1/2" tapped x 1/2" side tapped 19mm OD mount
7067A	1/2" tapped x 1/2" cross drilled 19mm OD mount
7067C	1/2" tapped x M10 cross tapped 19mm OD mount
7068A	1/2" tapped x 1/2" side tapped 25mm OD mount
7068D	1/2" tapped x 1/2" side drilled 25mm OD mount
7068C	1/2" tapped x M10 side tapped 25mm OD mount
7069A	1/2" tapped x 1/2" cross tapped 25mm OD mount
7069C	1/2" tapped x M10 cross tapped 25mm OD mount
7069D	1/2" tapped x 1/2" cross drilled 25mm OD mount
7069F	1/2" tapped x 1/2" 45' angle tapped 25mm OD mount
7165	1" dia body cap M10 centre hole
7166	1" dia body M10 centre 2 x M10 cross tapped holes
7167	1" dia body 1/2" 26tpi centre 2 x M10 cross tapped holes

Ball & Knuckle Joints

2000	1/2" M to 1/2" F anti-rotation brass ball joint
2002	M10 M to 1/2" F anti-rotation brass ball joint
2006	1/2" M x 1/2" M brass banjo knuckle joint
2007	M10 F x M10 F brass banjo knuckle joint
2010	M10 M x M10 F anti-rotation brass ball joint
2060	M10 M x M10 F brass 3/4" OD ball knuckle joint

Distance Spacers

SPE023	1.1/4" OD ball centre spacer 2" long 10mm hole
SPE024	1.1/4" OD waisted spacer tapped M10

CHAIN



Solid Brass Brazed Oval Link Chain

9024	1.1/4" long link
9025	1" long link
9026	3/4" long link
9027	5/8" long link
9028	1/2" long link
9165	1 1/2" brass S hook

Supplied bright brass finish. Chrome, nickel, bronze and old English brass finishes available.

Chain Open Link Steel Plated Finishes

9036	16mm open link brass plated
9036N	16mm open link nickel plated
9038	38mm open link brass plated
9038C	38mm open link Chrome plated
9038A	38mm open link Antique finish
9039	Open link Gothic Antique

ACCESSORIES



Brass Hooks and Rings

- 3071 ½" Male thread brass hook
- 3072 ½" Female thread brass hook
- 7069 M10 Male thread brass hook
- 7070 M10 Female thread brass hook
- 7071 M13 Male thread brass hook
- 7072 M13 Female thread brass hook
- 9203 M10 Female thread brass ring 22mm dia
- 9211 M10 Female thread brass balance ring 42mm wide
- 9218 M10 Female thread brass closed ring 45mm OD

Ceiling Hook Plates

- 3099R 65mm OD Ceiling hook plate polished brass
- 3099RE 65mm OD Ceiling hook plate polished brass earthed
- 9034 75mm OD 3 hook ceiling plate polished brass
- 1333 Bowl hook brass with washers and nut
- D590 Ceiling Hook zinc plated 73mm x 17mm

Finishes:

- Suffix 'C' - Chrome
- Suffix 'N' - Nickel
- Suffix 'Z' - Bronze
- Suffix 'H' - Old English Brass

Washers

- 9010 ½" x 1" OD brass
- 9010S ½" x 1" OD steel
- 9011 ½" x 7/8" OD steel internal teeth
- 9012 10mm x 21mm OD brass
- 9012S 10mm x 21mm OD steel
- 9013 ½" x 1" OD polyethylene
- 9014 13mm x ¾" OD red fibre
- 9015 10mm x 21mm red fibre
- 9017 10mm x 15mm steel internal teeth
- 9072 10mm x 25mm OD brass
- D811 10mm x 29mm steel

Earth Tag Rings

- 9005 13mm ID hole
- 9205 10mm ID hole

Cable Grips and Grommets

- 3200 ½" male thread brass taper cord grip
- 3201 M10 M/F brass side entry cord grip connector
- 3202 10mm male thread brass taper cord grip
- 9000 Plain side screw cord grip plastic
- 9001 M10 male side screw cord grip plastic
- 9002 M10 female side screw cord grip plastic
- 9003 10mm tube grommet polyprop
- 9003A 8mm tube grommet polyprop
- 9004 ½" tube grommet polyprop
- 9006 ½" tube end cable clamp polyprop
- 9007 10mm tube end cable clamp polyprop
- 9008 Fast Fit cable restraint
- 9201 M10 male taper cord grip
- 9202 M10 female taper cord grip
- 9301 10mm isolator cord grip
- 9307 10mm isolator tube grommet

Taps and Dies

- 9019 M10 x 1mm pitch HSS plug tap
- 9020 M10 x 1mm pitch HSS die
- 9021M M13 x 1mm pitch HSS plug tap
- 9022M M13 x 1mm pitch HSS die
- 9021 ½" x 26tpi HSS plug tap
- 9022 ½" x 26tpi HSS die

Miscellaneous

- 7117 10mm brass tube slide collar with screw
- 7200 M3 x 8mm dia brass knurled thumb screw
- 7201 5/32" whit x ½" long brass knurled gallery screw
- 7202 5/32" whit x ¾" long brass knurled gallery screw
- 7203 5/32" brass gallery bush fits 5.2mm hole
- 7204 M4 x 8mm dia brass knurled thumb screw

ACCESSORIES



Galleries

9221	2.1/4" dia 10mm hole polished brass 3 screw gallery
9231	3.1/4" dia 10mm hole polished brass 3 screw gallery
9241	4.1/4" dia 10mm hole polished brass 3 screw gallery
9229	2.1/4" dia 28mm hole polished brass 3 screw gallery
9239	3.1/4" dia 28mm hole polished brass 3 screw gallery
9249	4.1/4" dia 28mm hole polished brass 3 screw gallery

Finishes. Suffix 'C' chrome, 'Z' bronze, 'N' nickel, 'H' old English brass.

Steel Ceiling and Wall Plates

3145*	4.1/4" steel ceiling plate (*Suffix 'C' chrome, 'P' Polished Brass, 'A' Antique)
AC535/R	80mm dia 23mm high M10 tapped hole with 2" fixing centres steel
C237	100mm dia x 25mm chamfered steel cap either plain, 3 or 5 holes
C257	120mm dia 10mm centre hole steel side fix holes
D566/3W	120mm dia lampbase with 10mm lugs white powder coated
D580*	100mm Flat steel ceiling cap 10mm (*Suffix 'C' chrome, 'P' Polished Brass, 'A' Antique)
D581*	100mm Flat steel ceiling cap 1/2" (*Suffix 'C' chrome, 'P' Polished Brass, 'A' Antique)
D586*	100mm Steel ceiling cap (*Suffix 'C' chrome, 'P' Polished Brass, 'A' Antique)
F060	Large inner support plate 98mm dia 4 x 4ba tapped holes hole brass
H652/3	260mm dia steel cap cross strap fix 25mm deep
M001	85mm steel ceiling cap 10mm holes 2 csk holes
R100	100mm liner plate M3.5 side bushes
T099/1	80mm dia 23mm high M10 tapped hole Steel
T100	100mm dia 20mm deep cap 1/2" centre hole 2" csk fixing steel
T101	100mm dia 20mm deep cap 10mm centre hole steel

Brass Ceiling and Wall Plates

3098	1/2" x 26tpi tapped hole 2.5/8" Dia Polished Brass
3198	1/2" clear hole 2.5/8" Dia Polished Brass
3099	10mm clear hole 2.5/8" Dia Polished Brass
3099D	1/2" clear hole 2.5/8" Dia Polished Brass
3145B	4.1/4" raw brass ceiling cap 10mm hole
3199	10mm clear hole 3" Dia Polished Brass
C601	125mm x 76mm x 30mm deep Oval single hole cap brass
C608	125mm x 76mm x 30mm deep Oval double hole cap brass
D580B	100mm Flat ceiling cap raw brass 10mm hole
D657B	100mm dia 28mm deep brass islay cap 10mm centre hole
D658B	90mm dia 27mm deep brass islay cap 10mm centre hole
Q038	80mm dia 35mm deep ceiling rose brass
Q040	80mm dia 21mm deep flat ceiling rose brass
7150	5" brass base hole size to order

Strip Formed Products

C010	Saddle Bracket 10mm plain hole 68mm x 15mm
C257XS	117mm cross strap side tap M3 fits C257
C409	Cross strap for 100mm caps side tapped M3
C410	Saddle Bracket M10 tapped hole zinc plated 68mm x 15mm
C602	76mm Cross strap side tapped M3 fits C600 oval plate
C652	258mm Cross strap for H652
D594/1	10mm x 10mm lampholder fixing bracket 25mm x 40mm
D625	80mm cross strap side tapped M3 fits Q038/40
D614	Angled Cona bracket 44mm x 33mm
D619	2D bracket deep. 71mm x 30mm x h21mm
D781	Orbit fixing plate
D808	2D bracket 71mm x 30mm x h10mm
L100	98mm Earthed cross strap for D586
S061	L Bracket 2 x 10mm holes

Lamp Back Boxes and Centre Bodies

C402/2	Mini backbox with offset side bracket white powder coated
C423/W	Flat backbox with side L bracket white powder coated
C225/1	Long backbox with side bracket white powder coated
C417/1	Mini backbox with front L bracket zinc plated
D787	Flat backbox with front L bracket white powder coated
D660S	80mm Centre Body Cap 18mm deep Steel
D660B	80mm Centre Body Cap 18mm deep Brass
D661S	80mm 3 light Centre Body 35mm deep Steel
D661B	80mm 3 light Centre Body 35mm deep Brass
D667S	80mm 5 light Centre Body 35mm deep Steel
D667B	80mm 5 light Centre Body 35mm deep Brass
D668S	60mm dia 28mm high 3 hole cap 10mm centre hole steel
D668	60mm dia 28mm high 3 hole cap 10mm centre hole white

Heavy Steel Bases

D796/1	120mm Round Dish 10mm hole 3 x 1/2" Ball Feet
X100	100mm Square Plate 10mm hole 4 x 1/2" Ball Feet
X105	11.1/2" Round Plate 10mm hole 3 x 3/4" Ball Feet
X107	115mm Square Plate 10mm hole 4 x 3/4" Ball Feet

Half Caps

C331A	55mm half cap plain 10mm hole antique brass h10mm
C424C	70mm half cap beaded 10mm hole chrome plated h10mm

Formed Washers and End Caps

B250N	40mm dia stepped washer 10mm hole nickel plated
C240	50mm dome washer 29mm hole h5mm white powder coated
C400N	40mm to 29mm reducer washer zinc plated
C400W	40mm to 29mm reducer washer white powder coated
D567W	40mm to 10mm reducer washer white powder coated
D669	60mm glass holder washer 10mm hole white powder coated
7060	10mm hole brass fits 1" OD tube
7061	1/2" hole brass fits 1" OD tube
7260	Plain brass cap fits 2" OD tube
D629	10mm hole brass fits 30mm OD tube
D629/S	10mm hole steel fits 30mm OD tube
G900W	80mm cap 29mm hole h7mm white powder coated

Wall Switch Cover Plates

8031	Single Victorian Cover Plate Polished Brass Finish
8031C	Single Victorian Cover Plate Chrome Finish
8031G	Single Georgian Cover Plate Polished Brass Finish
8032	Double Victorian Cover Plate Polished Brass Finish
8032C	Double Victorian Cover Plate Chrome Finish
8032G	Double Georgian Cover Plate Polished Brass Finish

ACCESSORIES



ACCESSORIES



C407/S



C407/R



9033



D818



C246



C827



3130SSC



3130



S500



C401B



D644B



3128



3123



3141SP



D667



D660B



Q025



L302



F002B



S175B



S175



5342



S136B



S142B



Q020B



D789S



W701



W709



D656



3131SP



3132SP



SPE2V



3126



3129



D669



3140SP



OP304



9126

SWITCHES, PLUGS AND LEADS

Cups and Sconces

3123	10mm hole 70mm dia polished brass sconce
3124	½" hole 70mm dia polished brass sconce
3126	10mm hole 50mm dia beaded polished brass sconce
3127	10mm hole 70mm dia beaded polished brass sconce
3128	½" hole 70mm dia beaded polished brass sconce
3129	½" hole 50mm dia beaded polished brass sconce
3144	10mm hole 60mm dia rolled edge polished brass sconce
3130	10mm hole 70mm dia polished brass sconce plain
3130SSC	10mm hole 70mm dia steel sconce plain
3131SP	10mm hole 70mm dia polished brass plated steel sconce fluted
3132SP	10mm hole 70mm dia polished brass plated steel sconce hexagon
3140SP	10mm hole 55mm dia polished brass plated steel sconce fluted
3140SC	10mm hole 55mm dia brass sconce fluted
3141SP	10mm hole 55mm dia polished brass plated steel sconce plain
5342	Brass plain cup 25mm OD x 25mm high (G9)
9033	10mm hole 3.1/2" dia polished brass gallery pan
9126	10mm x 120mm spring shade clip
C407	100mm dia 10mm centre hole with side fixing holes Brass
C407/S	100mm dia 10mm centre hole with side fixing holes Steel
C407/R	100mm dia 10mm centre hole Ribbed with side fixing holes Brass
C246	90mm dia 20mm deep 10mm hole steel
C401	70mm dia pineapple rolled edge sconce ht13mm steel
C401B	70mm dia pineapple rolled edge sconce ht13mm brass
C827	80mm dia steel sconce 10mm hole
D667	80mm dia brass cup 33mm deep
D660B	80mm dia brass sconce 18mm deep
D644	60mm dia pineapple rolled edge sconce ht12mm steel
D644B	60mm dia pineapple rolled edge sconce ht12mm brass (3144)
D656	60mm dia lslay cap ht22mm steel
D656B	60mm dia lslay cap ht22mm brass
D789S	60mm dia cone cap ht16mm steel
D818	80mm dia 40mm high cup 10mm hole brass
F002B	55mm dia candle cup 10mm hole brass
L302	60mm dia ribbed sconce ht26mm brass
OP304	60mm dia x 17mm steel flat cap 10mm hole
Q020	60mm dia 23mm high cap steel
Q020B	60mm dia 23mm high cap brass
Q025	70mm dia glass holder cover ht27mm brass
S136B	10mm hole 35mm x 55mm high raw brass cup (BC)
S142B	10mm hole 43mm x 63mm high raw brass cup (ES)
S175	10mm steel bell cup 37mm x 45mm deep
S175B	10mm brass bell cup 37mm x 45mm deep
S500	70mm dia 18mm high steel ribbed domed sconce
S500B	70mm dia 18mm high brass ribbed domed sconce
SPE2V	55mm steel cone sconce brass plated
W701	66mm square pyramid sconce steel 10mm hole ht10mm
W709	50mm dia Smith Sconce steel

Switches Plugs & Dimmers

3864W	White Plastic 2way ceiling pull switch
3864B	Polished Brass finish 2 way ceiling pull switch
3864C	Chrome finish 2 way ceiling pull switch
3864A	Antique finish 2 way ceiling pull switch
135B	Push button switch black 10mm hole fix
135W	Push button switch white 10mm hole fix
7022	Brass cone switch cap for 135 push buttons
9018	UK 3pin plug protector
9200	Pull cord lever switch
9320G	Gold inline rocker switch
9320B	Black inline rocker switch
9320W	White inline rocker switch
9313	White UK plug top fitted 3 amp fuse
9313B	Black UK plug top fitted 3 amp fuse
9314	White Schuko Euro plug
9315	5 amp 3 pin plug white
9315B	5 amp 3 pin plug black
9314B	Black Schuko Euro plug
9420W	White inline dimmer 60-150w
9420B	Black inline dimmer 60-150w
9420G	Gold inline dimmer 60-150w
9435W	White foot switch
9435B	Black foot switch
9435G	Gold foot switch
RT81B	Black slider dimmer 60-300w

Plug Leads

PL25G	Gold UK plug lead 2.5m 3 amp fuse
PL25B	Black UK plug lead 2.5m 3 amp fuse
PL25W	White UK plug lead 2.5m 3 amp fuse
SC3100B150P	Black UK switched plug lead 2.5m 3 amp fuse
SC3100G150P	Gold UK switched plug lead 2.5m 3 amp fuse
SC3100W150P	White UK switched plug lead 2.5m 3 amp fuse



Miscellaneous

PN5TCE	5amp connector 12 section easy snap
20151	M3.5 x 35mm extension screws
3053	Adjustable copper earth strap
3215	15mm copper earth clamp
3222	22mm copper earth clamp
TAPE	Wiring instruction tape approx 300/roll
LABCE	CE self adhesive labels approx 1000/roll
LAB40W	40W self adhesive wattage labels approx 1000/roll
LAB60W	60W self adhesive wattage labels approx 1000/roll

Pre-Wired Lampholders quoted upon application

LED MODULE PRODUCTS



LM57SN



LM58Z



LM59C



LEDIP65

LED MODULE PRODUCTS

LEDIP65 1.2w Warm White Osram LED module M15 x 1 aluminium body IP65
Fitted with 200mm long leads 350mA
DX01 1.2w Warm white Osram Dragon 'X' LED Module 350mA
DX01LENS LED Lens to suit DX01 Dragon 'X' LED Module
SERIAL CONNECTIONS ONLY.
Must be used with electronic 350mA constant current power supply.

LM51 Open front LED mount M15 with retainer spring
LM52 Open front LED mount baffled M15 with retainer spring
LM53 Contemporary Eyelid mount M15 with retainer spring
LM56 Surface LED mount M15
LM57 Up/Down LED mount M15 with 50mm dia plate fix
LM58 Down LED mount M15 with 50mm dia plate fix
LM59 Swivel LED mount M15
LM1WL Flush mount LED flexi arm fitting
UY2 Mini waterproof push button quick connector.

The above mounts do not include the LEDIP65 module.
Flush module covers require 20mm dia cut out.

Finishes:

Suffix 'C'	Chrome
Suffix 'Z'	Bronze
Suffix 'N'	Nickel
Suffix 'PL'	Polished Brass
Suffix 'H'	Old English brass



LM53CS



DX01
LENS



DX01



LM56



LM51C



LM53H



UY2



LM SPRING



LM51




LM53Z



LM53W

LED LIGHT SOURCES

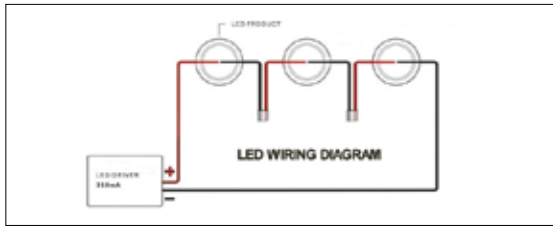

IMPORTANT 'MUST READ' NOTES REGARDING LED'S

1. Driver powered LED products must be wired in series. (See diagram)
2. If the power supply is connected to the mains before the LED connections have been made, turn off the mains supply and short circuit the output terminals. This is because of a large stored voltage ramp that exists in an open circuit situation that would burn out the LED's as soon as they are connected.
3. All switching on LED circuits must take place on the mains side of the power supply and not the output for the reasons stated above.



350MA CONSTANT CURRENT POWER SUPPLIES

With thermal overload, overcurrent and short circuit protection

- | | |
|-----------|---|
| PTDCC/3 | 95v – 240v input supply for up to 3 x 1watt LED |
| PTDCC/10 | 95v – 240v input supply for up to 8 x 1watt LED |
| PTDCC/15 | 95v – 240v input supply for up to 12 x 1watt LED |
| LEDICC350 | 100 – 240v input supply for up to 1 x 1.2watt LED IP67 rated potted |

SHADE ACCESSORIES



BRASS SHADES

- | | |
|------|---|
| 9322 | Brass Shell shade raw finish 7.5" X 4.5" 28mm hole |
| SH04 | Brass Coolie Shade raw finish 250mm x 110mm deep. 50mm hole with beaded edge, fits 2.¼" gallery |
| 9461 | Brass Bell gallery 6 ¼" dia x 3 ¾" deep polished |



HARP SHADE CARRIERS

- | | |
|--------|---------------------------------------|
| LL504P | 4" fixed harp brass plated 28mm hole |
| LL504C | 4" fixed harp chrome plated 28mm hole |
| LL506P | 6" fixed harp brass plated 28mm hole |
| LL506C | 6" fixed harp chrome plated 28mm hole |
| LL508P | 8" fixed harp brass plated 28mm hole |
| LL508C | 8" fixed harp chrome plated 28mm hole |
| H4004P | 4" fixed harp brass plated 40mm hole |
| H4006P | 6" fixed harp brass plated 40mm hole |
| H4008P | 8" fixed harp brass plated 40mm hole |

LAMP ASSEMBLY SERVICE



LAMP ASSEMBLY SERVICE

We offer a lamp assembly service to assist our customers in achieving their production targets.

All lamps are constructed to meet the requirements of BS EN 60598 under our LA Code of Practice approval.

We offer a prompt and efficient service utilising 'Lilley' components.

Please enquire for further details.



TUBES



Brass tubes can be supplied to order in the following sizes. 1", 5/8", 1/2", 10mm and 8mm in raw, polished or plated finishes.

- T12COVPL Coventry tube bend Polished and Lacquered 6" x 3"
- T12WARPL Warwick twin arm tube bend Polished and Lacquered
- T12DONPL Doncaster tube bend Polished and Lacquered 8 1/2" x 9"
- T12WREPL Wrexham tube bend Polished and Lacquered 9" x 4"
- S10109 S arm assembly M10 centre fix 7" wide raw
- S10209 S arm assembly 1/2" centre fix 7" wide raw
- "S" ARM Variations are custom made to order.
- DOG LEGS Custom made to order.

KNOBS



Polished Brass Victorian Shutter Knobs

50013W	½" diameter woodscrew fix
50020W	¾" diameter woodscrew fix
50025W	1" diameter woodscrew fix
50032W	1.1/4" diameter woodscrew fix
50038W	1.1/2" diameter woodscrew fix
50025M	1" diameter M5 bolt fix
50032M	1.1/4" diameter M5 bolt fix
50038M	1.1/2" diameter M5 bolt fix.
50025T	1" diameter cupboard turn
50032T	1.1/4" diameter cupboard turn
50038T	1.1/2" diameter cupboard turn

Polished Brass Patterned Shutter Knobs

40020W	¾" diameter Sheraton woodscrew fix
40025W	1" diameter Sheraton woodscrew fix
40032W	1.1/4" diameter Sheraton woodscrew fix
40025M	1" diameter Sheraton M5 bolt fix
40032M	1.1/4" diameter Sheraton M5 bolt fix
70025W	1" diameter Imperial woodscrew fix
70032W	1.1/4" diameter Imperial woodscrew fix
70025M	1" diameter Imperial M5 bolt fix
70032M	1.1/4" diameter Imperial M5 bolt fix

Door Furniture

770SP	Plain oval square plate set
770RP	Plain oval round plate set
770LP	Plain oval lock plate set
742	Dot & Dash square plate set
760	Floral square plate set
800	Plain Escutcheon.

BLISTER PACKED PRODUCTS

Certain Lilley products are available in clamshell blister packs for point of sale retail displays. Please enquire for availability.





S. Lilley & Son Limited

80 Alcester Street
Birmingham
B12 0QE
England

Tel: 0121 622 2385
Fax: 0121 666 6148
E-mail: sales@s-lilley.co.uk

www.s-lilley.co.uk



QUALITY AND SERVICE FROM A FAMILY BUSINESS