

P-touch 2100VP



Brother P-touch labels have been subjected to a series of rigorous tests which prove that even when they're exposed to extreme conditions, they will last and last. They are truly Tested to the Extreme!



Laminated

Laminated – our unique laminated tape technology ensures that a layer of super-clear polyethylene laminate protects your text.



Temperature Resistant

Temperature Resistant – P-touch labels can withstand extreme temperatures, from -80°C to 150°C.



Strong Adhesion

Strong Adhesion – specially developed adhesive means P-touch labels will stay firmly affixed to a wide range of surfaces.



Abrasion Resistant

Abrasion Resistant – In the P-touch abrasion test using a 1kg sanding device, lettering remained completely intact, only the protective layer was slightly scratched.



Chemical Resistant

Chemical Resistant – after being submerged for 2 hours in a variety of chemical substances, no change in appearance or structure of P-touch labels occurred and the labels remained affixed.



Water Resistant

Water Resistant – after submersion in water over a long period, the tape structure and adhesive strength of P-touch labels remained unchanged.



Fade Resistant

Fade Resistant – after a year in a simulated sunny climate P-touch labels showed very little change visible to the naked eye.



Easy Peel

Easy Peel – enables convenient removal of the tape backing before applying the label.

Technical Information

Hardware

Housing Dimensions (mm)	177(W) x 231(D) x 64(H)
Housing Design	Desktop
Housing Weight	820g (without batteries)
Housing Colour	Silver & Black
Keyboard	QWERTY
Number of Keys	65
Cutter	Fully automatic
Power	AA sized Alkaline Batteries x 6pcs or AC Adapter Model AD-24 (included)
LCD	16 Chr. x 3 lines
Tape Type	TZ tape
Tape Size	3.5, 6, 9, 12, 18mm
Print Head	180 dpi
Print Speed	10mm/sec


Built-In Software

Built in Fonts	4 (Helsinki, Brussels, Florida, Calgary)
Built in Languages	English, French, German, Dutch, Italian, Spanish, Portuguese, Danish, Swedish, Norwegian, Finnish, Hungarian, Czech, Polish
Number of CHR S & Symbols	392
Memory Size	1800 characters (maximum 9 locations)
Max. Print Height	15.8mm
Max. Character Height	14.8mm
Multi-Line printing	5 lines
Type Styles	Normal/Bold/Outline/Shadow/Solid/Italic Italic Bold/Italic Outline/Italic Shadow/Italic Solid
Framing & Fill Pattern	15 Frames / 1 Fill Pattern
Underline	Yes
Strikeout	Yes
Tape Margin Settings	Small/Large/Chain Printing/No Cut
Barcode Protocols	CODE39, CODE128, EAN8, EAN13, EAN128, UPC-A, UPC-E, I-2/5(1TF), CODABAR
Mirror Printing	Yes
Vertical Printing	Yes
Copy Printing	1~9
Numbering	1~9
Auto Power Off	Yes
Function Menu	Yes

At your side.
brother®

P-touch 2100VP

Electronic Labelling System
with PC connection

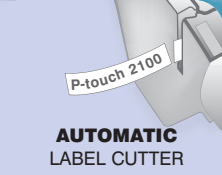

PC USB CONNECTION




CARRY CASE INCLUDED



AC ADAPTER INCLUDED



AVAILABLE TAPE SIZES

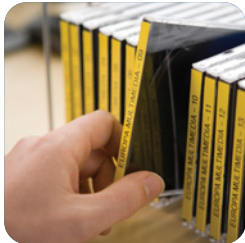

Always at your side



P-touch



The P-touch 2100VP - your perfect office companion!

P-touch 2100VP Features

- ## Easy to use yet has many advanced features

Share with work colleagues or keep it all to yourself!

 
The P-touch 2100VP's compact size and lightweight design make it ideal to share with your work colleagues...or keep it just for yourself! It comes with a handy, durable storage case with space to keep the AC adapter that comes supplied with it, plus a full length 18mm width black on white TZ tape.

Design and print labels directly from your computer

Connect the P-touch 2100VP to your computer and use the supplied P-touch Editor label design software to create, edit and print labels directly from your PC.


Durable labelling

Brother's unique and exceptionally durable TZ tapes are designed to be extra hard wearing. Tests have shown that these tapes can withstand heavy abrasion, lengthy exposure to chemicals, sunlight, water and extreme temperatures, from -80 to 150°C.



Why do Brother P-touch labels last longer ?

Consisting of six layers of material, the Brother laminated TZ tapes results in a thin, yet extremely strong label. Characters are formed with thermal transfer ink and sandwiched between two layers of PET (polyester film), which allows for the creation of virtually indestructible labels. No other labels offer such resistance and wear!

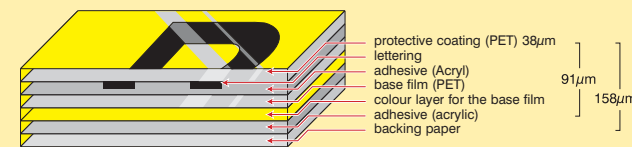

Brother Laminate Tape Construction

So that you can start labelling immediately, we provide a full length, 18mm TZ labelling tape with the P-touch2100VP. This tape gives you many labelling possibilities in and around the office or workplace. And because our labels are so durable, you can be sure that they will be perfectly readable year after year.



Wide Range of Tapes

TZ tapes are available in a large range of colours and widths. Standard tape length is 8m providing approximately 100 labels*! For full tape line-up see TZ tape catalogue.



Within the TZ tape range we also offer special tapes, including:

Strong Adhesive Tape - Gives improved adhesion for those even more demanding applications and environments.

Flexi ID Tape - Ideal for cylindrical surfaces and flagging cables.

Security Tape - Designed to leave a checkerboard pattern as an indicator that the tape has been removed.

Fabric Iron-On Tape - Produces washable cloth labels ideal for labelling uniforms, work wear, bedding and table cloths.

*based on 10 characters and standard label length of 8cm.

