



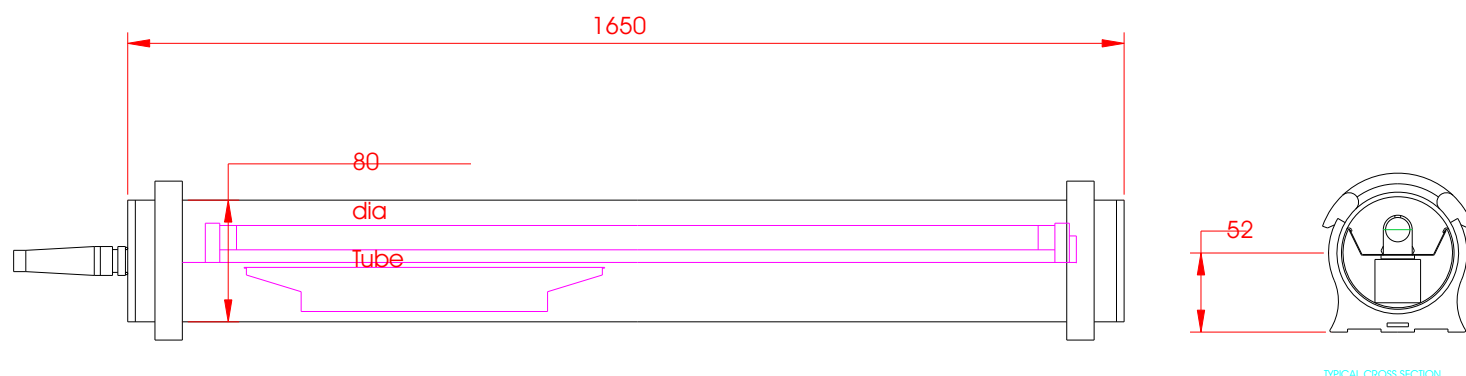

EDL Lighting Ltd

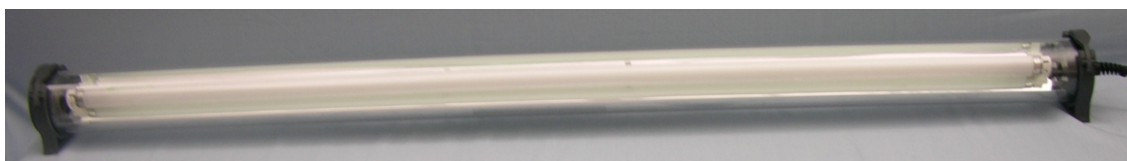

Version: Tubelight-80-IP67-58W-T8-230/240V

RS Order Code: 794-3480

The waterproof tubelight is tested to Ip67 and comes complete with brackets and trailing lead. The main body tube is manufactured from impact resistant polycarbonate. This unit has many applications within the manufacturing and food industries as well as marine environments. The plastic end caps are secured using stainless steel screws to ensure not only a watertight seal but also a unit that will resist corrosion.

Main features:

Impact resistant polycarbonate tube
Compact fluorescent tube
Suitable for machine mounting - withstands coolant spray onto light unit
Design facilitates ease of cleaning
Trailing lead fitted as standard

Made in United Kingdom- all spares available

High IP rating IP67
Clamps and ballasts included
Other marine and waterproof applications

Can be used in dusty environments
Clip on brackets securing straps - no tools needed

Other voltages & wattage available

Primary Voltage: 230/240v 50/60 Hz
End Cap material: Moulded PVC
Ballast: High frequency Electronic
Brackets Supplied: Yes
Plug Fitted : No
IP rating: IP67
Fixing: Can be Horizontal or Vertically mounted
RHOS Compliant: Yes

Lamp Type: Linear Fluorescent (T8)
Lamp Wattage: 58W
Lamp Base: Linear 2 pin
Trailing Cable: Yes approx 2.7m
Switch Fitted: No
Tube Material: Polycarbonate 80mm Dia
Manufacturing Standard: BS EN 60598
Wee Compliant: Yes

EDL Lighting Limited, Redbrook lane, Brereton, Rugeley, Staffs WS15 1QU

Telephone: +44(0)1889 582112

Fax: +44(0)1889 584012

Email: sales@edl-lighting.co.uk Website www.edl-lighting.co.uk