


Deep groove ball bearings, single row, shield on both sides



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	-
7	19	6	2,34	0,95	0,04	85000	43000	0,0075	607-2Z *

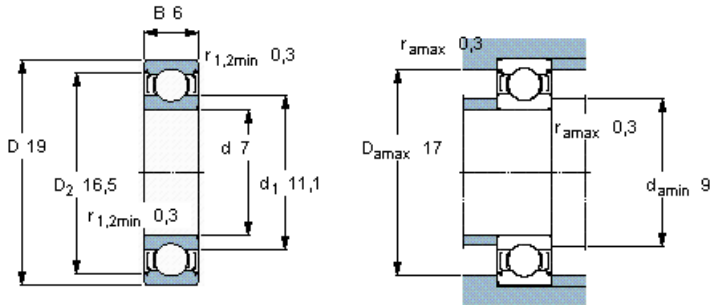

Calculation factors

k_f 0,025
 f_0 13