


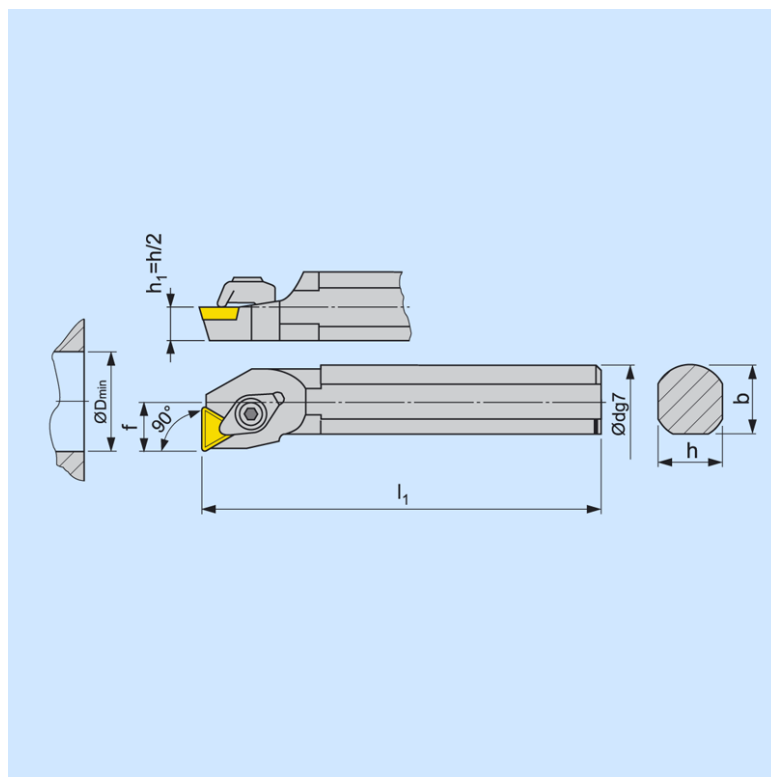

?	Specification	dg7	f	l1	h	b	Dmin	λ_s [°]	γ_o [°]	kg	Side
○	S16M-CTFPL 11	16	11	150	14,5	15	20	0	0	0.25	L
●	S16M-CTFPR 11	16	11	150	14,5	15	20	0	0	0.25	R
○	S20Q-CTFPL 11	20	13	180	18	18,5	25	0	0	0.45	L
●	S20Q-CTFPR 11	20	13	180	18	18,5	25	0	0	0.45	R
○	S25T-CTFPL 16	25	17	300	23	23	32	0	0	1.15	L
●	S25T-CTFPR 16	25	17	300	23	23	32	0	0	1.15	R
○	S32U-CTFPL 16	32	22	350	30	30	40	0	0	2.10	L
●	S32U-CTFPR 16	32	22	350	30	30	40	0	0	2.10	R