

Housing - HC-B 10-TFL-H-O1PG21S - 1460049

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON B10 sleeve housing, for single locking latch, height: 72 mm, with 1 x Pg21 gland, lateral cable outlet



Key commercial data

| | |
|--------------------------------------|--|
| Packing unit | 10 pc |
| GTIN |  4 046356 695428 |
| Weight per Piece (excluding packing) | 22.22 g |
| Custom tariff number | 85389099 |
| Country of origin | Germany |
| Note | Made to Order (non-returnable) |

Technical data

Dimensions

| | |
|--------|-------|
| Height | 72 mm |
| Width | 43 mm |
| Length | 73 mm |

Ambient conditions

| | |
|--------------------------------------|-------------------|
| Degree of protection of housing (IP) | IP65 |
| Ambient temperature (operation) | -40 °C ... 125 °C |

General

| | |
|------------------------------|--|
| Note | For contact inserts HC-B10, BB18, DD42, M, K8/24 |
| Type | B10 |
| Housing type | Sleeve housing |
| Locking type | for single locking latch |
| No. of cable outlets | 1 |
| Cable exit | Lateral |
| Screw connection | none |
| Type of the screw connection | 1x Pg21 |

Housing - HC-B 10-TFL-H-O1PG21S - 1460049

Technical data

General

| | |
|--------------------------|-------------------------------------|
| Housing material | Aluminum die-cast |
| Housing surface material | Powder-coated, gray |
| Assembly instructions | For half and full screw connections |

Classifications

eCl@ss

| | |
|------------|----------|
| eCl@ss 4.0 | 27140816 |
| eCl@ss 4.1 | 27140816 |
| eCl@ss 5.0 | 27143424 |
| eCl@ss 5.1 | 27143424 |
| eCl@ss 6.0 | 27143424 |
| eCl@ss 7.0 | 27440209 |
| eCl@ss 8.0 | 27440202 |

ETIM

| | |
|----------|----------|
| ETIM 3.0 | EC000437 |
| ETIM 4.0 | EC000437 |
| ETIM 5.0 | EC000437 |

UNSPSC

| | |
|---------------|----------|
| UNSPSC 6.01 | 31261502 |
| UNSPSC 7.0901 | 31261502 |
| UNSPSC 11 | 31261502 |
| UNSPSC 12.01 | 31261502 |
| UNSPSC 13.2 | 31261502 |

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approvals submitted

Approval details

Housing - HC-B 10-TFL-H-O1PG21S - 1460049

Approvals

EAC

Accessories

Accessories

Full screw connection

Cable gland - G-INS-PG21-M68N-PNES-GY - 1411145



Cable gland, Cable gland material: Polyamide, External cable diameter 13 mm ... 18 mm, Shielding: No, Connecting thread: Pg21, Color: silver grey

Cable gland - G-INS-PG21-M68N-NNES-S - 1411175



Cable gland, Cable gland material: Brass, nickel-plated, External cable diameter 13 mm ... 18 mm, Shielding: No, Connecting thread: Pg21, Color: silver

Cable gland - G-INSEC-PG21-M68N-NNES-S - 1411200



Cable gland, Cable gland material: Brass, nickel-plated, External cable diameter 13 mm ... 18 mm, Shielding: Yes, Connecting thread: Pg21, Color: silver

Plug for cable screw gland

Filler plugs - HC-BS-PG21 - 1674529




Filler plugs, for Pg screw connections, type Pg21

Drawings

Housing - HC-B 10-TFL-H-O1PG21S - 1460049

Dimensioned drawing

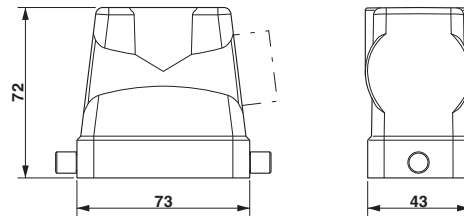

Dimensional drawing

Phoenix Contact 2015 © - all rights reserved
<http://www.phoenixcontact.com>