


Comus Group of Companies

PRODUCT DATA SHEET

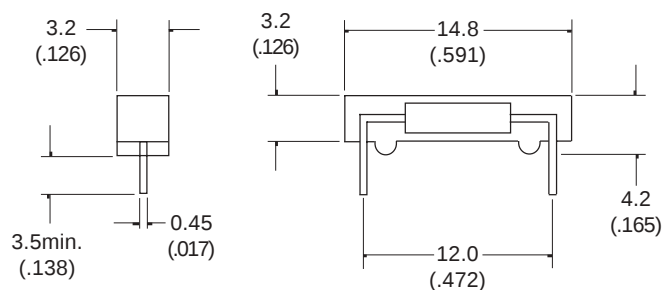

Drawings not to scale
 All dimensions in mm (inches) nominal.
 Tolerance = +/- 0.2mm

SPECIFICATION

CONTACT FORM/STYLE		Open
SWITCHING VOLTAGE	Max. Vac	24
SWITCHING CURRENT	Max. A	0.1
SWITCHING CAPACITY	Max. VA	1.0
CONTACT RESISTANCE	Max. mΩ	200
SWITCHING DISTANCE	Min. mm	Dependant on magnet
OPERATING TEMPERATURE	Deg. °C	-20° +70°
STORAGE TEMPERATURE	Deg. °C	-25° +70°
CASE MATERIAL		Polypropylene

PROXIMITY SENSORS

PART NUMBER
PPS 24

Rev. No.	Revision Note	Date	Signature
C	Web Site 2003	10-6-03	RG

The Comus Group of Companies
 consist of:

Assemtech Europe Limited
 Comus International
 Gunther Belgium
 Gunther France

As part of the company policy of continued product improvement, specifications may change without notice. Our sales office will be pleased to help you with the latest information on this product range and details of our full design and manufacturing service. All products are supplied to our standard conditions of sale otherwise agreed in writing.