

Datasheet

Case Cable Reel

RS Stock number 889-2497




Specifications:

Standard(s):	EN 61242
Maximum Load:	10A: Wound Wattage = 900W/230V, Unwound Wattage=2,300W/230V 16A: Wound Wattage = 1,000W/230V, Unwound Wattage = 3,000W/230V
Switch Specification:	16A 125V/250V~
Thermal cut-out:	56 ± 5 °C
Max cable length:	H05VV-F 10A(1.0mm ²) = 25m, H05VV-F 16A(1.5mm ²) = 15m

Product Information

Part No.:	889-2497
Type:	Case Reel
Cable Type:	H05VV-F
Cable Length (m):	15
Amp:	16
Product Dimensions(cm):	H:21.8 x W:20.6 x D17.2

Line Diagram:

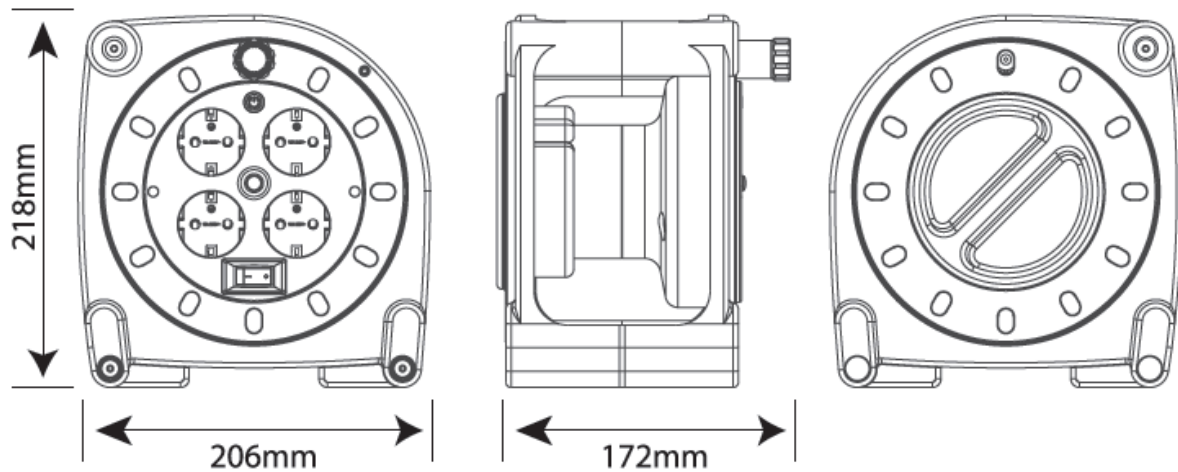

Features

- Robust open reel, with four Schuko type sockets
- Space saving style
- Thermal cut-out protection
- Power on/off switch
- Power LED indicator
- Manufactured to EN 61242
- 5 year guarantee