


Cable connector - UC-19S1N1280DU - 1606685

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)

Cable connector, straight, Shielded, Screw locking, M23, Number of positions: 16+3, Type of contact: Socket, Solder connection



Key commercial data

Packing unit	1
GTIN	 4 046356 261203
Custom tariff number	85366990

Technical data

Product type	Circular connector (cable-side)
Coding	N
Type	Cable connector
Number of positions	19
Thread	M23
Rated voltage (IEC)	150
Rated current (IEC)	10
Knurl material	Metal
Shielding	Yes
Signal type	Signal
Connection method	Solder connection

Classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260708
eCl@ss 7.0	27440312
eCl@ss 8.0	27440312

ETIM

ETIM 3.0	EC001121
ETIM 4.0	EC001121

Cable connector - UC-19S1N1280DU - 1606685

Classifications

ETIM


ETIM 5.0	EC002641
----------	----------

UNSPSC

UNSPSC 6.01	43172015
UNSPSC 7.0901	43201404
UNSPSC 11	43172015
UNSPSC 12.01	43201404
UNSPSC 13.2	43201404

Drawings

Schematic diagram

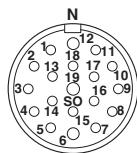

Dimensioned drawing

