

## Display Series

VIA

# VID-2215

15" Vision Intelligence  
Display Industrial Touch LCD  
Monitor



## Features

- 15" Color TFT LVDS LCD module, with LED backlight driver
- High Brightness of 400 cd/m<sup>2</sup>
- XGA 1024 x 768 native mode
- VGA & HDMI signal input (The HDMI port will only support display input function, but not available for audio input.)
- Light Weight by aluminum housing design
- Wall mount VESA screw holes: 75 x 75, 100 x 100 (mm)
- IP65 compliant front panel protects against water and dust
- 5-wire resistive touch screen

## Specifications

Part Number	VID-2215-1R1A1	
<b>Display Specifications</b>	<b>LCD Display</b>	15" Color TFT LVDS LCD module, with LED backlight driver
	<b>Resolutions (pixel)</b>	1024 x 768, XGA
	<b>Active Area</b>	304.128 (H) x 228.096 (V)
	<b>Pixel Pitch</b>	0.29 x 0.29 (mm)
	<b>Luminance</b>	400 cd/m <sup>2</sup>
	<b>Contrast Ratio</b>	700 : 1 (typical )
	<b>Support Color</b>	262k
	<b>Lamp Life Time</b>	50000
	<b>Viewing Angle</b>	160°/140° (H/V)
	<b>Response Time</b>	8ms (tf + tr)
	<b>Input Signal</b>	R/G/B Analog
	<b>Signal Type</b>	15-pin D-sub
	<b>OSD Controls/Button</b>	Power, auto, menu / enter, up, down
	<b>Power Consumption</b>	28W (Max.) /Standby under 4W
<b>Power Management</b>	VESA DPMS	
<b>AC/DC Adapter</b>	Input: AC 100~240, 50~60HZ; Output: DC 12V/ 3.0A	
<b>Touch Screen Options</b>	5-wire resistive ant glare	
<b>Mechanical Specifications</b>	<b>Construction</b>	Aluminum
	<b>Mounting Options</b>	Desktop, wall mount, and panel mount
	<b>Dimensions</b>	382mm (W) x 301mm (H) x 49mm (D)
<b>Environment</b>	<b>Operating Temperature</b>	-10°C up to 70°C
	<b>Operation temperature with adapter</b>	0 up to 40°C
	<b>Operation temperature without adapter</b>	-10 up to 70°C
	<b>Relative Humidity</b>	0 ~ 85% @ 40°C
	<b>EMC Approved</b>	CE, FCC
<b>Front Panel Protection</b>	IP65 compliant	

## Ordering Information

Part Number	Description
VID-2215-1R1A1	15" Industrial 5-Wire Resistive Touch LCD Monitor


## Optional Accessories

\*Note: The optional accessories may have minimum ordering quantity limitation. Please contact VIA Sales representative for more details.

<b>Mounting Plate</b>	
Part Number	Description
99G42-090154	Desktop stand
99G42-090164	Wall-mount bracket



## Dimensions

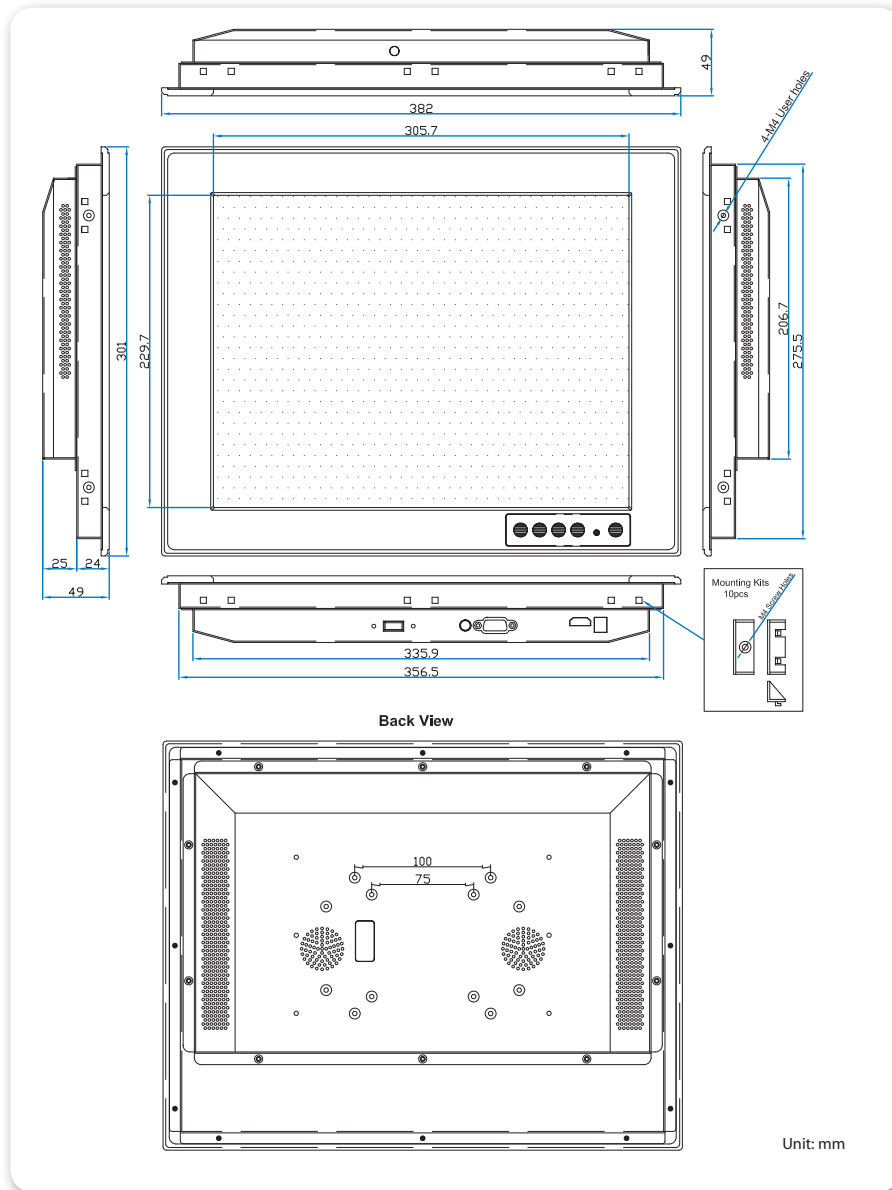

## Packing List

- 1 x VGA cable
- 1 x AC power adapter
- 1 x AC power cable ( USA Type )
- 1 x AC power cable ( Europe Type )
- 1 x Touch screen USB cable/ touch pen/ driver CDROM
- 1 x Panel mount brackets