




# Active 320S

## White Dual Control Electric Showers

The Active 320S has a unique dual control, combining power select and on/off rotary flow/temperature control. Developed with contemporary 'S-line' styling and smart technology this shower comes complete with single mode handset and riser rail kit all in chrome.

- Application** Day to day showering.
- Key Features** 3 power settings with LED power on indicator | Top, bottom or rear entry access for cable and cold water supply.
- Safety Features** Fully temperature stabilised with 'Smart Stop®' hot water purge reducing scale and ensuring cool start | Dual concentric rotary controls for on/off and power selection | Overheat protection | Electric solenoid operation on/off | Temperature and flow control with single turn valve | Removable corner section for ease of installation.
- Outer Casing** Polar white | High impact | Easy clean | Scratch resistant | Thermoplastic.
- Accessories** Chrome accessory kit: Single rub-clean handset | Soap dish | Hose retaining ring | Riser rail | Height adjustable clamp.
- Pressure** Operating pressure - 0.7bar - 7bar.
- Approvals** BEAB Approved | CE.
- Guarantee** 1 year product guarantee (UK).

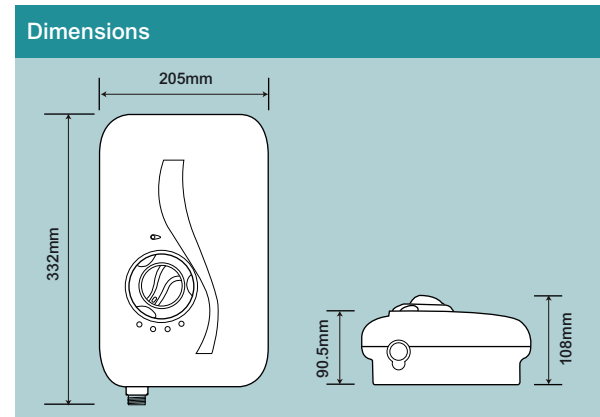

**Technical Specification** Operating water pressure 0.7-7bar (10-100psi) | Water pressure operated power switch | Water connection - standard 15mm inlet connection | Top, bottom or rear cable entry options | Removable corner section for ease of installation.

kW variant	kW loading at 230-240V	Recommended cable sizes	Recommended fuse ratings
7.2	6.6 - 7.2	4 - 6mm <sup>2</sup>	30 amps
8.5	7.8 - 8.5	6 - 10mm <sup>2</sup>	40 amps

### Product Range

Product Reference	Short Code	Cat. No
Active 320S 7.2kW	A3207S	53670501
Active 320S 8.5kW	A3208S	53671001
Extended Control Lever	LEV3	83595325

