 


**Murale IP 54. Recessed step lights. TC 11 W**

Fixed recessed step lights – with HPF ballast – for compact fluorescent lamps; prismatic safety shield; high performance, metallised polycarbonate reflector; die-cast aluminium front to UNI 5076; Pegaso finish. (For control gear technology details, see page 348-353)





STANDARD FINISHES

black-graphite gloss [26]

white gloss [27]



metallised grey [28]

	CONTROL GEAR	WATT	LAMP	LAMPHOLDER	BEAM WIDTH	IP	CLASS	APPROVALS	KG
6112	HPF	11	TC	G 23	asymmetric	54	[26]	[27] [28]	1.00

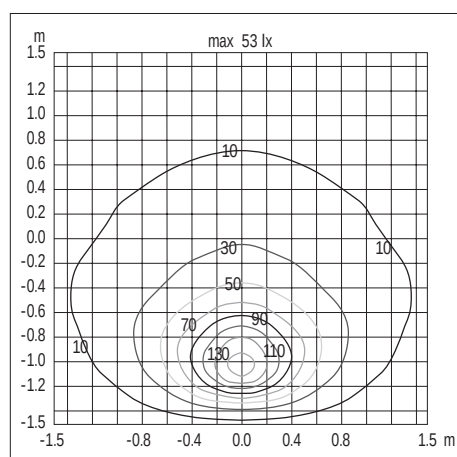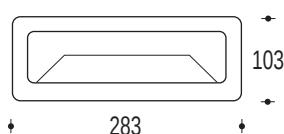

Isolux with luminaire at 75 cm above ground level

WITH LOUVRE	CONTROL GEAR	WATT	LAMP	LAMPHOLDER	BEAM WIDTH	IP	CLASS	APPROVALS	KG
6135	HPF	11	TC	G 23	asymmetric	54	[26]	[27] [28]	1.06

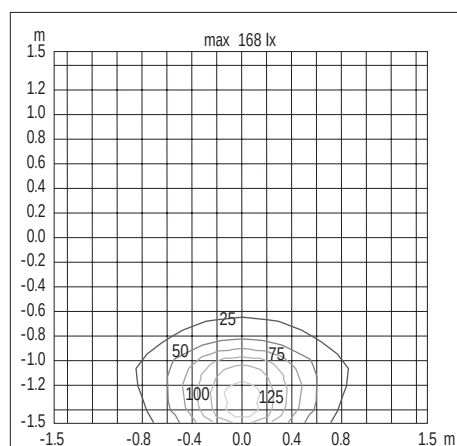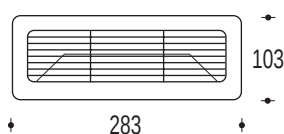

Isolux with luminaire at 75 cm above ground level

ACCESSORIES

WALL BOX 110x228x85mm

REFERENCES
FINISHES

6014