

Mini-Lynx Fast-Start

ML FAST-START 840 E27 23W SLV

0035130

Range features



CE

PRODUCT OVERVIEW

Ordering number	0035130
Technology	Compact Fluorescent
Light colour	840 Cool White
Energy class	A
Average life (Rated) (h)	10000
Lamp shape	Stick
Lamp finish	frosted
Dimmable	No
Cap/Base	E27
Type	Mini-Lynx Fast Start T3 4U Stick
EAN code	5410288351308
CRI (Ra)	80
Colour temperature (K)	4000
Luminous flux (Rated) (lm)	1450
Efficacy (Rated) (lm/w)	63.04
Watt (Nominal) (W)	23
Equivalent watt (W)	104
Voltage (V)	230-240

Mini-Lynx Fast-Start

ML FAST-START 840 E27 23W SLV

0035130

DATA TABLE

General data

Ordering number	0035130
Dry applications use only	Yes
Technology	Compact Fluorescent
Average life (Rated) (h)	10000
Average life (Nominal) (h)	10000
Energy class	A
Energy saving lamp	Yes
Lamp shape	Stick
Lamp finish	frosted
Dimmable	No
Cap/Base	E27
Type	Mini-Lynx Fast Start T3 4U Stick
EAN code	5410288351308
E-number FI	4940290
E-number SE	8357553
Long description	
Product name	ML FAST-START 840 E27 23W SLV
Lamp mercury content (mg)	<2.5
Starting time (max) (s)	< 1.0 Sec
Warm-up time to 60% of full light (max) (s)	< 40 s
Control gear required	No
IEC Reference	IEC 60968
IEC Reference 2	IEC 60969
IEC Reference 3	IEC 55015
ILCOS code	FBTH-23/40/1b-E27-48/148
Intended purpose	General lighting
No. of switching cycles before premature failure (min)	30000
Special purpose lamp	No
Transformer required	No
Sales pack quantity	10
Optimal operating condition (°C)	25° C, cap-up, Stated lumen output may vary if operated in non-standard position

Mini-Lynx Fast-Start

ML FAST-START 840 E27 23W SLV

0035130

Optical data

Light colour	840 Cool White
CRI (Ra)	80
Colour temperature (K)	4000
Lumen maintenance at end of nominal life (%)	= 75.0 %
Luminous flux (Nominal) (lm)	1450
Luminous flux (Rated) (lm)	1450
Chromaticity coordinate X	0.38
Chromaticity coordinate Y	0.38
Rated lumen maint. factor at 6000 h	= 80.0 %

Electrical data

kWh per 1000 hours burning time	23
Efficacy (Rated) (lm/w)	63.04
Watt (Nominal) (W)	23
Watt (Rated) (W)	23
Equivalent watt (W)	104
Voltage (V)	230-240
Current (A)	0.185
Lamp power factor	> 0.55

Physical data


Weight (kg)	0.09
Lamp Length (mm) - C/L	148
Max. Lamp Diameter (mm) - D	48
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	16.50 x 4.80 x 4.80
Outer package dimensions (L x W x H) (cm)	25.30 x 11.00 x 18.50

Mini-Lynx Fast-Start

ML FAST-START 840 E27 23W SLV

0035130

TECHNICAL DRAWINGS

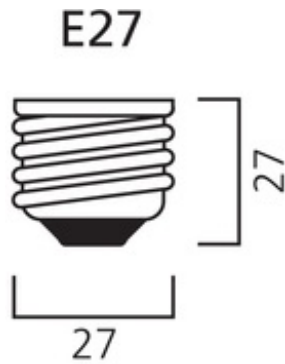

ENERGY LABEL

