


Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed		* SKF Explorer bearing
mm			kN		r/min		-
<b>38,1</b>	65,088	18,034	42,9	57	7500	11000	LM 29749/710/QCL7CVA60

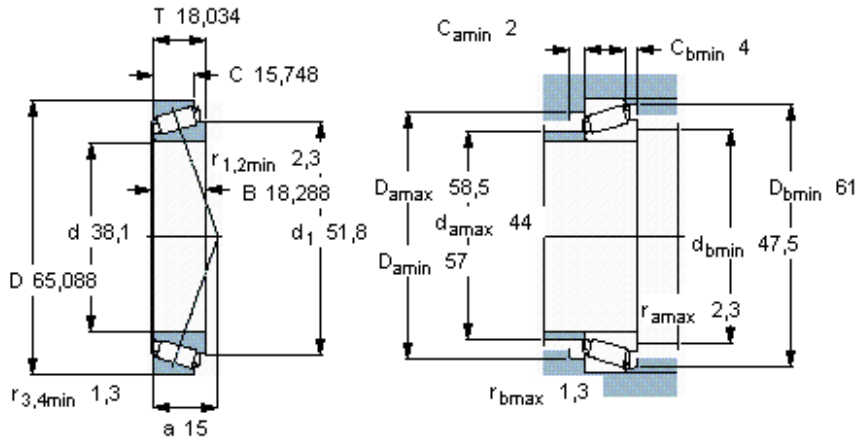

**Calculation factors**

e 0,33  
 Y 1,8  
 Y<sub>0</sub> 1