

ABSOLUTE Digimatic Solar Caliper


Series 500

ABSOLUTE®



This solar-powered Digimatic caliper is a standard model that enables you to take reliable measurements. The ABSOLUTE Digimatic Solar Caliper offers you the following benefits:

- You can operate it in just 60 lux ambient lighting.

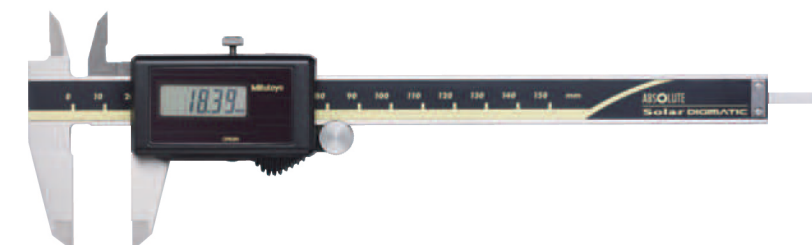

500-444



500-457

Metric


Without thumb roller

No.	Range [mm]	Depth bar	Data output	L [mm]	a [mm]	b [mm]	c [mm]	Mass [g]
500-457	0-150	flat		233	40	21	16.5	150
500-458	0-200	flat		290	50	24	20	180

Metric

With thumb roller

No.	Range [mm]	Depth bar	Data output	L [mm]	a [mm]	b [mm]	c [mm]	Mass [g]
500-453	0-100	Ø 1,9 mm		182	40	21	16.5	125
500-443	0-100	Ø 1,9 mm		182	40	21	16.5	145
500-454	0-150	flat		233	40	21	16.5	150
500-444	0-150	flat		233	40	21	16.5	170
500-455	0-200	flat		290	50	24	20	180
500-445	0-200	flat		290	50	24	20	200

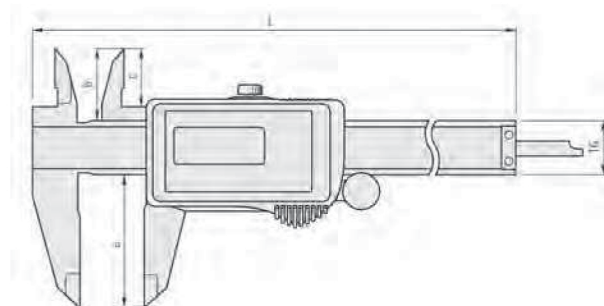


Functions	Series 500
ORIGIN (ABS-Zero)	

Specifications

Accuracy	±0,02 mm (excluding quantizing error)
Max. response speed	Unlimited
Power	Solar cell
Digital step	0,01 mm
Display	LCD; Character Height 7,5 mm
Delivered	In a case

Optional accessories

No.	Description
959149	Digimatic cable with data switch (1 m)
959150	Digimatic cable with data switch (2 m)
02AZD790C	U-WAVE Data Cable with data switch
06ADV380C	USB Input tool Direct cable with data switch (2 m)
959143	Data-hold unit
050083-10	75 base for depth measurement for models up to 200
050084-10	100 base for depth measurement for models up to 200

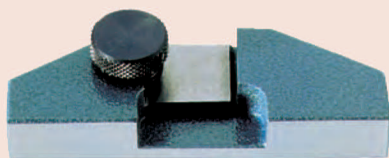

050083-10