

Colour Laser Multifunctional Printer

i-SENSYS
MF8350Cdn

you can



Boost your business with impressive colour and productivity.

Use the power of high performance, professional colour communication to grow your business, thanks to this productive, energy-saving unit.

20 PPM COLOUR
& MONO PRINTING
& COPYING

PAPER CAPACITY
MAX. 550-SHEET

QUICK
FIRST-PRINT

UP TO
2400 X 600 DPI
PRINT RESOLUTION

5-LINE
LCD DISPLAY

AUTOMATIC
DOUBLE-SIDED
PRINTING

Key features

- Compact colour laser All-in-One: print, fax, copy and scan
- 20 ppm/cpm in colour and mono
- Superior colour imaging technologies for crisp text and vibrant colours
- Up to 2400 x 600 dpi print resolution
- Automatic double-sided printing
- No waiting with Quick First-Print technologies
- User friendly 5-line LCD display
- Easy scan to network and to USB memory key
- 50-sheet ADF, 250-sheet cassette, 50-sheet multi-purpose tray, 250-sheet optional cassette
- Energy efficient - only 3 watts in sleep mode
- Convenient All-in-One colour cartridges

What's in the Box

Main unit, Cartridge 718 starter C/M/Y/K, power cord, telephone line cable, starter guide and warranty card - with user software and manual CDs.

Dimensions (W x D x H)

430 x 484 x 479 mm

Supported OS

Windows 2000/Server 2003/
Server 2008/XP/Vista
Mac OS X Version 10.4.9 - 10.5.x
(Web distribution only, network
scanning not supported)



PRINT



COPY



FAX




SCAN

Canon

i-SENSYS MF8350Cdn

Specifications

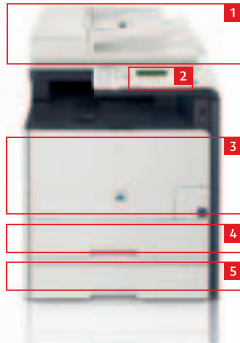

- 1 Flatbed & 50-sheet ADF**
- 2 5-line LCD display**
- 3 50-sheet multi-purpose tray**
- 4 250-sheet cassette**
- 5 Optional 250-sheet cassette**
- 6 Cartridge 718**
(4 colours available: Cyan, Magenta, Yellow and Black, and Black Value Pack available)

Machine type Available functions	Colour Laser All-In-One Print, Copy, Scan and Fax
PRINTER Print speed Printing method Print quality Print resolution Double sided printing Printer languages Print margins Toner saver mode	Up to 20 ppm colour and mono (A4) Colour laser beam printing Up to 2400 x 600 dpi with Automatic Image Refinement 600 x 600 dpi Automatic UFRII-LT 5 mm-top, bottom, left and right Yes
COPIER Copy speed First Copy Output Time (FCOT) Copy resolution Copy modes Double sided copying Multiple copy Reduction / Enlargement Other features	Up to 20 cpm colour and mono (A4) Approx. 16 seconds or less Up to 600 x 600 dpi Text/Photo/Map (Default), Text/Photo/Map (quality), Printed Image, Text 1-sided to 2-sided (Manual) Up to 99 copies 25-400% in 1% increments Frame Erase, Collate, 2 on 1, 4 on 1, ID card copy
SEND FUNCTIONS Scan to USB memory key File formats	Yes PDF
SCANNER Type Scan resolution Colour scanning depth Greyscales Compatibility Max. scan width	Colour Optical: Up to 600 x 600 dpi Enhanced: Up to 9600 x 9600 dpi 24 bit/24 bit (input/output) 256 levels TWAIN, WIA 216 mm
FAX Modem speed Receive mode Fax resolution Fax memory Speed dials Group dials/destinations Sequential broadcast Memory backup Double sided faxing Other features	Super G3 33.6kbps (Up to 3 seconds/page ¹) Fax only, Fax/Tel Auto Switch, Answer Mode, Manual RX Standard: 200 x 100 dpi Fine: 200 x 200 dpi Photo: 200 x 200 dpi Super fine: 200 x 400 dpi Ultra fine: 400 x 400 dpi Up to 512 pages ¹ Max. 200 (including 19 one-touch dials) Max. 199 dials / Max. 199 destinations Max. 201 locations 5 mins Yes (Receive/ Transmit (Manual)) Fax Forwarding, Dual Access, Remote Reception, PC Fax (TX only)
MEDIA HANDLING Scanner type Paper input (Standard) Paper input (Option) Paper output Media types	Flatbed and Automatic Document Feeder (ADF) 250-sheet cassette 50-sheet multi-purpose tray 50-sheet ADF 250-sheet cassette 125-sheet Plain paper, Recycled paper, Heavy Paper, Transparency, Coated Paper, Label, Index card, Envelope

Media sizes	Cassette and optional cassette : A4, A5, B5, Legal, Letter, Executive, Statement, Envelope (COM10, DL, ISO-C5, ISO-B5), Custom sizes: Width 100 to 215.9 mm; Length 148 to 355.6 mm Multi-purpose tray: A4, A5, B5, Legal, Letter, Executive, Statement, Envelope (COM10, Monarch, DL, ISO-C5, ISO-B5), Custom sizes: Width 76.2 to 215.9 mm; Length 127.0 to 355.6 mm ADF: A4, A5, B5, Legal, Letter, Statement, Custom sizes (W x L): Max. 215.9 mm x 355.6 mm Min. 128 mm x 139.7 mm
Media weights	Cassette: 60 to 163 g/m ² Manual feed slot: 60 to 220 g/m ² ADF: 50 to 105 g/m ²
INTERFACE & SOFTWARE Interface type Operating System compatibility Software and printer management	USB 2.0 Hi-Speed, 10BASE-T/100BASE-TX Windows 2000/ Server 2003/ Server 2008/ XP/ Vista Mac OS X version 10.4.9 - 10.5.x ^{2, 3} Presto! Page Manager, MF Toolbox, NetSpot Device Installer, Remote User Interface (RUI), Department ID Management
GENERAL FEATURES Duty cycle Warm-up Time Memory Control panel Dimensions with trays (W x D x H) Installation space (W x D x H) Weight Operating environment Power Source Power Consumption Noise Levels	Max. 40,000 pages per month Approx. 23 seconds from power on 128MB (shared) 5 lines backlit LCD 430 mm x 484 mm x 479 mm 674 mm x 1327 mm x 851 mm 679 mm x 1327 mm x 951 mm (with optional 250-sheet paper cassette) Approx. 31 Kg Temperature: 10 to 30°C (50 to 86°F) Humidity: 20 to 80% RH (no condensation) 220-240V (±10%) 50/60Hz (±2Hz) Maximum: Approx. 1200 W Standby: Approx. 25 W Sleep mode: Approx. 3 W Typical Electricity Consumption (TEC): 1.0 kWh/week Sound Pressure: Active: 67 dB(A) or less Standby: 46 dB(A) or less
CONSUMABLES Cartridges	Cartridge 718 Black (3,400 pages ⁵) ⁶ Cartridge 718 Cyan (2,900 pages ⁵) ⁶ Cartridge 718 Magenta (2,900 pages ⁵) ⁶ Cartridge 718 Yellow (2,900 pages ⁵) ⁶
ACCESSORIES/ OPTIONS Items	CST.FEEDING UNIT-V1 (250-sheet cassette) TEL 6 KIT LONG CORD (Telephone handset)
All specifications subject to change without notice	
¹ Based on ITU-T Standard Chart No. 1 ² Web distribution only ³ Network scanning not supported ⁴ Declared noise emission in accordance with ISO 9296 ⁵ Based on ISO/IEC 19798 ⁶ Printer ships with 1,200 pages K (Black) and 1,400 pages CMY (Cyan, Magenta and Yellow) starter cartridges	




**Office Technology Irl. Ltd.,
Unit G9, Riverview Business Park,
Nangor Road,
Dublin12.
Tel: +353 1 460 4444
Fax: +353 1 460 3333
www.officetechnology.ie**

Colour Laser Multifunctional Printer

i-SENSYS
MF8350Cdn

you can

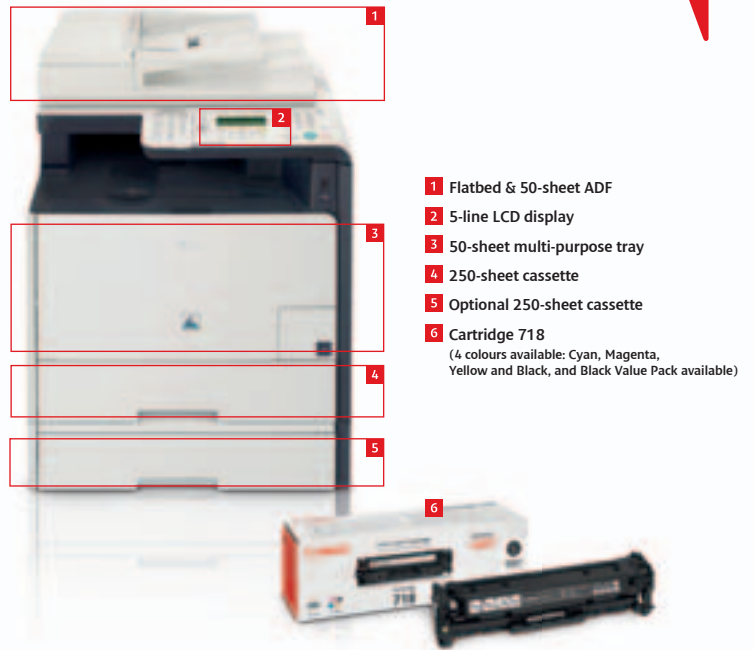

- 1 Flatbed & 50-sheet ADF
- 2 5-line LCD display
- 3 50-sheet multi-purpose tray
- 4 250-sheet cassette
- 5 Optional 250-sheet cassette
- 6 Cartridge 718
(4 colours available: Cyan, Magenta, Yellow and Black, and Black Value Pack available)

**Boost your business with
impressive colour and productivity.**
The i-SENSYS MF8350Cdn is part of the Canon
Colour Laser Multifunctional Printer range.

Sales Start Date: November 2009

The whole range consists of:

Colour: MF8030Cn, MF8050Cn,
MF8330Cdn,
MF8350Cdn, MF8450,
MF9130, MF9170

Box Dimensions (W x D x H)

800 x 710 x 710 mm

Box weight

Approx. 66kg

Packet style Quantity

Pallet —
20ft Container —
40ft Container —

MERCURY CODES

PRODUCT			
Name	Mercury Code	EAN Code	
MF8350Cdn	[MER]	[EAN]	
OPTIONS			
Accessories			
Cassette Feeding Unit-V1	0732A024AA	4960999643755	
Telephone 6 Kit EU (CW)	0752A054AA	4960999453910	
Telephone 6 Kit UK (CW)	0752A053AA	4960999453897	
Telephone 6 Kit SA (CW)	0752A055AA	4960999453927	
CONSUMABLES			
Toner			
Cartridge 718 C Cyan (2,900 pages*)	2661B002AA	4960999628608	
Cartridge 718 M Magenta (2,900 pages*)	2660B002AA	4960999628578	
Cartridge 718 Y Yellow (2,900 pages*)	2659B002AA	4960999628547	
Cartridge 718 B Black (3,400 pages*)	2662B002AA	4960999628639	
Cartridge 718 B VP Black Value Pack (6,800 pages*)	2662B005AA	4960999653433	
EASY SERVICE PLAN			
Details			
3yr on-site next day service M4	093ZZ331	8714574979809	
Installation Service N2	093ZZ326	8714574979755	

* Based on ISO/IEC 19798



PRINT



COPY



FAX



SCAN

Canon