


DOC NO	ISSUE	REVISION	PRODUCT REF.	DATE	QUALITY PLAN
QF/RD/05	01	00	FAR0708	18.09.14	
TECHNICAL SPECIFICATIONS				SIGNATURE	
				PRESIDENT (TECHNICAL)	

RETRIEVAL FALL ARRESTER BLOCK(FAR0708)

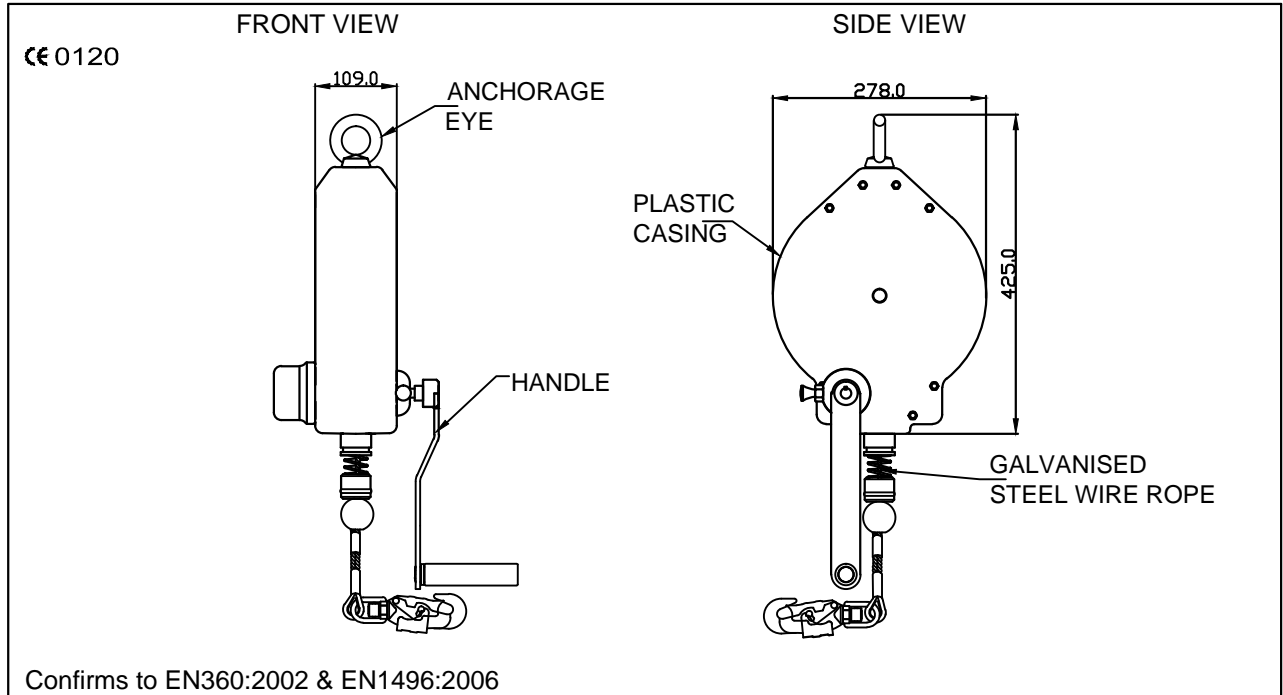

DESIGN

- Retrieval fall arrester block in polymer casing which is coupled with hoisting winch to enable easy retrieval of victim.
- The Block allows the fall to arrest and also allows easy hoist of the victim with the help of its hoist handle.
- The locking pin on the side of the casing at the base of the handle allows this dual system to work in independent fall arrest & winch modes.
- Can be easily mounted on the leg of 'KARAM TRIPOD PN800A' using specialized bracket Ref. PN800A(09).

PHYSICAL PARAMETERS

- Robust & durable plastic casing.
- Has swivel anchorage eye at anchorage end.
- Steel swivel hook with Load Indicator Ref. PN-123 at attachment end.
- Galvanised steel wire rope (option of having S.S. wire rope available)

LENGTH

- | | |
|---------------|-----------------|
| Reference no. | Length of cable |
| FAR0708 | 30 Meters |

(Special lengths also available on request subject to a minimum of 25 meters & maximum of 30 meters.)

CABLE

- Material : Galvanised steel wire rope Ø4.5 (Min.)
- Breaking strength : 15 KN or 1,530 kgf (Min.)

MINIMUM BREAKING STRENGTH

- 12 KN or 1,225 kgf

NORM

- Meets EN-360:2002 & EN1496:2006

WEIGHT

- FAR0708 : 14.80 kg

