





Data Specification Sheet

ENGLISH

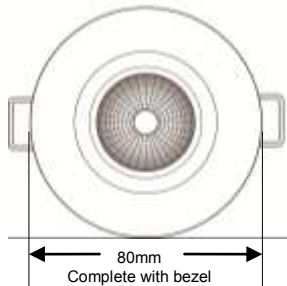

Shown with Bezel (not included)

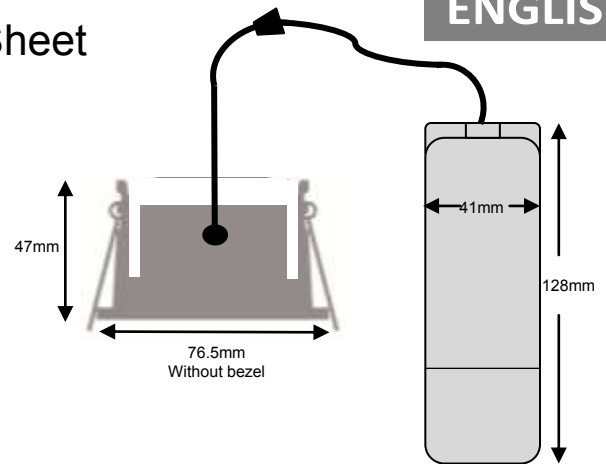

IP65 LED Fire Rated Downlight c/w Dimmable Driver

Description	IP65 LED Fire Rated Downlight c/w Dimmable Driver		
Code	851-2968 Warm White IP65 LED Fire Rated Downlight 851-2980 Cool White IP65 LED Fire Rated Downlight		
Code – Bezel Only	858-0958 – Matt White Bezel	858-0942 – Brass Bezel	858-0949 – Chrome Bezel 858-0945 – Brushed Chrome Bezel
Bezel Diameter	80mm		
Rim Diameter	76.5mm		
Cut Out	64mm		
Minimum Depth (Void)	75mm		
Total length of driver lead	300mm		
Weight	0.29Kg		
Recommended product location	Indoor Outdoor		
Finishes available (Bezels sold separately)	Matt White, Brass, Chrome, Brushed Chrome		
Control Gear Type	8W 180mA SELV LED Dimmable Driver supplied pre-wired to downlight		
Lamp Supplied	Fixed non-replaceable 8W COB LED		
Class	Class II. Must not be Earthed		
IP	IP65		
Photometric Testing	Yes		
Lumen Output	460lm Warm White – 530lm Cool White		
Beam Angle	38°		
Dimmable	Yes		
Instruction sheet	Yes		
Origin of manufacture	China		
Main materials:			
• Chassis	Pressed Steel		
• Body	Die cast		
• Bezel	Die cast		
Method of fix	Twin fixed spring		
Electrical Connections	Loop in 10Amp L.N. + Earth Park Nylon Connector, Push-in Terminals		
CE mark	Yes		
Batch coding details on product	Yes		
Certificate of Conformity (Held on File)	Yes		
Manufactured in accordance	EN60598-1 General requirements EN60598-2-1 Fixed general purpose luminaires EN60598-2-2 Recessed luminaires BS5250 (Energy efficiency, Useful heat loss and passage of condensation), BS ISO 10140 : Acoustics : Building Elements Part P (Installation requirements) BS476 – Part 21 & Part 23 Fire rating		