


SKF ConCentra ball bearing, metric shafts
d 25 – 45 mm

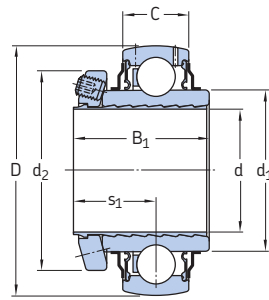

Dimensions							Basic load ratings		Fatigue load limit	Limiting speed	Mass	Designation
d	D	B ₁ ¹⁾	C	d ₁	d ₂	s ₁ ¹⁾	dynamic	static				
mm		-		-			kN		kN	r/min	kg	-
25	52	33	15	33,7	41,7	21,0	14	7,8	0,335	7 000	0,18	E2.YSP 205 SB-2F
30	62	37	18	39,7	48	23,0	19,5	11,2	0,475	6 300	0,3	E2.YSP 206 SB-2F
35	72	39,5	19	46,1	57	24,3	25,5	15,3	0,655	5 300	0,44	E2.YSP 207 SB-2F
40	80	42,9	21	51,8	62	25,9	30,7	19	0,8	4 800	0,59	E2.YSP 208 SB-2F
45	85	44	22	56,8	67	26,5	33,2	21,6	0,915	4 300	0,64	E2.YSP 209 SB-2F

¹⁾ Width/distance before the grub screw is tightened (sleeve and inner ring bore at starting position).