



Self-aligning ball bearings, cylindrical and tapered bore, cylindrical bore, unsealed

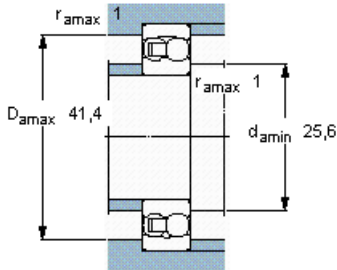

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	-
20	47	14	12,7	3,4	0,18	32000	20000	0,12	1204 ETN9

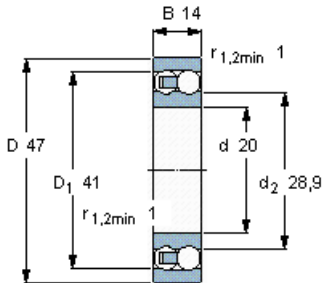

Calculation factors

- e 0,3
- Y_1 2,1
- Y_2 3,3
- Y_0 2,2