

## Passive module - FLKM-2KS40/SPT/CS/C-L - 2321855

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



1:1 interface module for YOKOGAWA AAV 141, AAV 142, AAT 141, AAI 141, AAI 143 analog I/O modules, AAV 542, AAI 543, AAI 841, AAB 841, AAI 135, AAP 135, AAI 835 and AAR 181. Redundant system connection, spring-cage connection on the field side.

The figure shows version  
FLKM-2KS40/SPT/CS



### Key commercial data

Packing unit	1 pc
GTIN	 4 046356 350648
Weight per Piece (excluding packing)	355.0 g
Custom tariff number	85369010
Country of origin	Germany
Note	Made to Order (non-returnable)

### Technical data

#### Dimensions

Width	194.5 mm
Height	126 mm
Depth	40 mm

#### Ambient conditions

Ambient temperature (operation)	-20 °C ... 50 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C

#### General

Max. permissible operating voltage	24 V DC ±10 %
Max. perm. current (per branch)	1 A
Mounting position	any
Assembly instructions	In rows with zero spacing
Standards/regulations	DIN EN 50178
Rated surge voltage	0.8 kV

# Passive module - FLKM-2KS40/SPT/CS/C-L - 2321855

## Technical data

### General

Pollution degree	2
Surge voltage category	III

### Connection data for connection 1

Connection name	Field level
Connection method	Spring-cage connection
Conductor cross section solid min.	0.2 mm <sup>2</sup>
Conductor cross section solid max.	4 mm <sup>2</sup>
Conductor cross section stranded min.	0.2 mm <sup>2</sup>
Conductor cross section stranded max.	2.5 mm <sup>2</sup>
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	12

### Connection data for connection 2

Connection name	Controller level
Number of connections	1
Connection method	Yokogawa KS-compatible
Number of positions	40

### Supported controller

Controller	YOKOGAWA CENTUM CS3000R3
- suitable I/O card	AAV141
	AAV142
	AAI141
	AAI143
	AAV542
	AAI543
	AAI135
	AAI835
	AAP135
	AAT141
	AAR181
	AAB841
Controller	YOKOGAWA STARDOM
- suitable I/O card	NFAI141
	NFAI43
	NFAI543
	NFAI135
	NFAP135
	NFAV141
	NFAV142
	NFAV542

## Passive module - FLKM-2KS40/SPT/CS/C-L - 2321855

### Technical data

#### Supported controller

	NFAB841
	NFAI841
	NFAI835

### Classifications

#### eCl@ss

eCl@ss 4.0	27250313
eCl@ss 4.1	27250313
eCl@ss 5.0	27250313
eCl@ss 5.1	27250313
eCl@ss 6.0	27242608
eCl@ss 7.0	27141152

#### ETIM

ETIM 2.0	EC001434
ETIM 3.0	EC001604
ETIM 4.0	EC001604
ETIM 5.0	EC002780

#### UNSPSC

UNSPSC 6.01	30211824
UNSPSC 7.0901	39121421
UNSPSC 11	39121421
UNSPSC 12.01	39121421
UNSPSC 13.2	39121421

### Accessories

#### Accessories

##### System cable

Cable - FLK 40-PA/EZ-DR/KS/ 100/YUC - 2322786



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 1.0 m

## Passive module - FLKM-2KS40/SPT/CS/C-L - 2321855

### Accessories

Cable - FLK 40-PA/EZ-DR/KS/ 200/YUC - 2314341



Round cable set, with two 40-pos. molded socket strips (1:1 connection). Length of cable: 2.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/ 300/YUC - 2314354



Round cable set, with two 40-pos. molded socket strips (1:1 connection). Length of cable: 3.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/ 400/YUC - 2314367



Round cable set, with two 40-pos. molded socket strips (1:1 connection). Length of cable: 4.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/ 500/YUC - 2321570



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 5.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/ 600/YUC - 2314943



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 6.0 m

---

## Passive module - FLKM-2KS40/SPT/CS/C-L - 2321855

### Accessories

Cable - FLK 40-PA/EZ-DR/KS/ 700/YUC - 2321583



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 7.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/ 800/YUC - 2314956



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 8.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/ 900/YUC - 2321415



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 9.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/1000/YUC - 2314370



Round cable set, with two 40-pos. molded socket strips (1:1 connection). Length of cable: 10.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/1100/YUC - 2321428



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 11.0 m

---

## Passive module - FLKM-2KS40/SPT/CS/C-L - 2321855

### Accessories

Cable - FLK 40-PA/EZ-DR/KS/1200/YUC - 2321431



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 12.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/1300/YUC - 2321444



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 13.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/1400/YUC - 2321457



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 14.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/1500/YUC - 2314383



Round cable set, with two 40-pos. molded socket strips (1:1 connection). Length of cable: 15.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/1600/YUC - 2321596



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 16.0 m

---

## Passive module - FLKM-2KS40/SPT/CS/C-L - 2321855

### Accessories

Cable - FLK 40-PA/EZ-DR/KS/1700/YUC - 2321606



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 17.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/1800/YUC - 2321619



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 18.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/1900/YUC - 2321622



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 19.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/2000/YUC - 2314532



Round cable set, with two 40-pos. molded socket strips (1:1 connection). Length of cable: 20.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/2500/YUC - 2314545



Round cable set, with two 40-pos. molded socket strips (1:1 connection). Length of cable: 25.0 m

---

## Passive module - FLKM-2KS40/SPT/CS/C-L - 2321855

### Accessories

Cable - FLK 40-PA/EZ-DR/KS/3000/YUC - 2314558



Round cable set, with two 40-pos. molded socket strips (1:1 connection). Length of cable: 30.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/3500/YUC - 2901017



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 35.0 m.

---

Cable - FLK 40-PA/EZ-DR/KS/4000/YUC - 2901052



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 40.0 m.

---

Cable - FLK 40-PA/EZ-DR/KS/4500/YUC - 2902912



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 45.0 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/ 100/YUC - 2904747



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 1 m

---

## Passive module - FLKM-2KS40/SPT/CS/C-L - 2321855

### Accessories

Cable - FLK 40-PA/EZ-DR/HF/KS/ 200/YUC - 2904748



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 2 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/ 300/YUC - 2904749



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 3 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/ 400/YUC - 2904750



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 4 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/ 500/YUC - 2904645



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 5 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/ 600/YUC - 2904751



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 60 m

---

## Passive module - FLKM-2KS40/SPT/CS/C-L - 2321855

### Accessories

Cable - FLK 40-PA/EZ-DR/HF/KS/ 700/YUC - 2904752



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 7 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/ 800/YUC - 2904753



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 8 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/ 900/YUC - 2904754



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 9 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/1000/YUC - 2904646



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 10 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/1500/YUC - 2904647



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 15 m

---

## Passive module - FLKM-2KS40/SPT/CS/C-L - 2321855

### Accessories

Cable - FLK 40-PA/EZ-DR/HF/KS/2000/YUC - 2904488



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 20 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/2500/YUC - 2904648



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 25 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/3000/YUC - 2904649



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 30 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/3500/YUC - 2904650



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 35 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/4000/YUC - 2904651



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 40 m

---

# Passive module - FLKM-2KS40/SPT/CS/C-L - 2321855

## Accessories

Cable - FLK 40-PA/EZ-DR/HF/KS/4500/YUC - 2904652



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 45 m


Cable - FLK 40-PA/EZ-DR/HF/KS/5000/YUC - 2904653



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 50 m

## Drawings

Dimensioned drawing

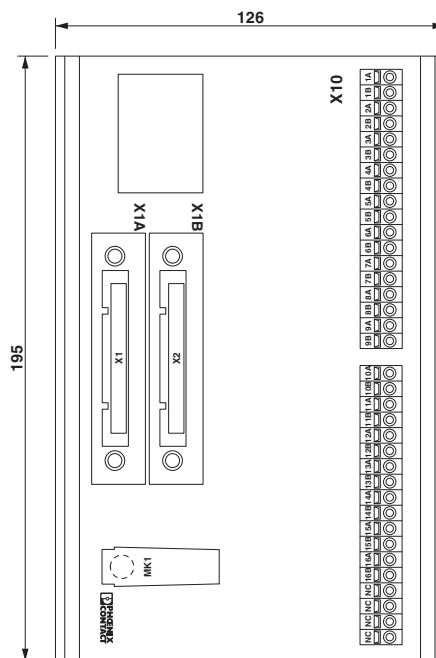

# Passive module - FLKM-2KS40/SPT/CS/C-L - 2321855

Circuit diagram

