



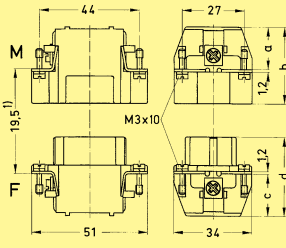
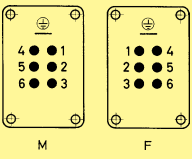
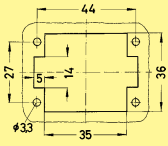



Number of contacts

6 +

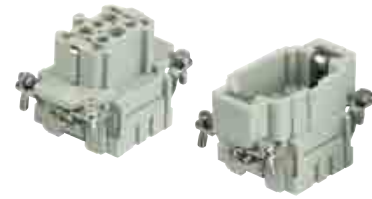

Inserts

Han E/EE

Identification	Series	Part number		Drawing	Dimensions in mm																				
		Male insert (M)	Female insert (F)																						
<p><b>Crimp terminal</b></p> <p>Order crimp contacts separately (see Technical characteristics on page 03.03)</p> 	Han E®	<b>09 33 006 2602</b>	<b>09 33 006 2702</b>		<p>1) Distance for contact max. 21 mm</p> <table border="1"> <thead> <tr> <th></th> <th>a</th> <th>b</th> <th>c</th> <th>d</th> </tr> </thead> <tbody> <tr> <td>Han E® screw</td> <td>18</td> <td>33</td> <td>18</td> <td>35</td> </tr> <tr> <td>Han® ES / Han E® crimp</td> <td>19</td> <td>34</td> <td>19</td> <td>36</td> </tr> <tr> <td>Han® ESS</td> <td>34</td> <td>49</td> <td>32</td> <td>49</td> </tr> </tbody> </table> <p>Contact arrangement view from termination side</p>  <p>Panel cut out</p> 		a	b	c	d	Han E® screw	18	33	18	35	Han® ES / Han E® crimp	19	34	19	36	Han® ESS	34	49	32	49
	a	b	c	d																					
Han E® screw	18	33	18	35																					
Han® ES / Han E® crimp	19	34	19	36																					
Han® ESS	34	49	32	49																					
<p><b>Screw terminal with wire protection</b></p> 	Han E®	<b>09 33 006 2601</b>	<b>09 33 006 2701</b>																						
<p><b>Cage-clamp terminal</b></p> 	Han® ES	<b>09 33 006 2616</b>	<b>09 33 006 2716</b>																						
<p><b>Cage-clamp terminal two terminals per contact</b></p> 	Han® ESS	<b>09 33 006 2672</b>	<b>09 33 006 2772</b>																						