


Type UI 39/10,2 14 VA

Range available ex stock*


VDE 0551/EN 60742
 Potted under vacuum
 Split-bobbin transformers
 Temperature class t_a 40°C/E

- * Other primary and secondary voltages on request
- * Other temperature classes on request
- * CCA-Certificate available
- * Weight 0,315 kg
- * Fixing material for \square 0,098 inch (2,5 mm):
 Self-tapping screws DIN 7513 (M 3 x 8...)
 Sheet-metal screws DIN 7971 (2,9 x 6,5...)

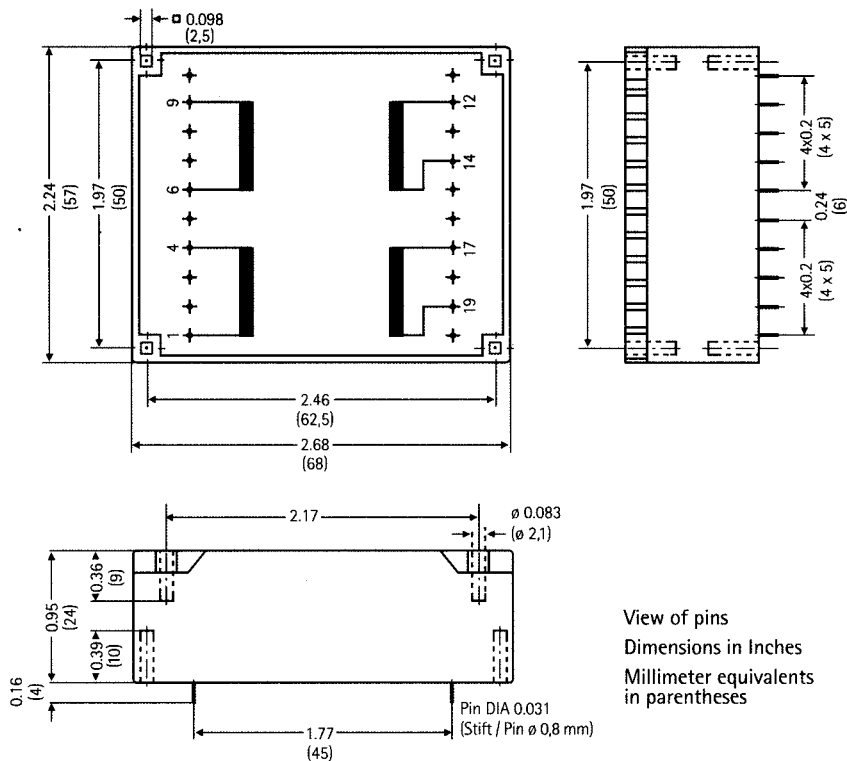

View of pins
 Dimensions in Inches
 Millimeter equivalents in parentheses

Connection possibilities

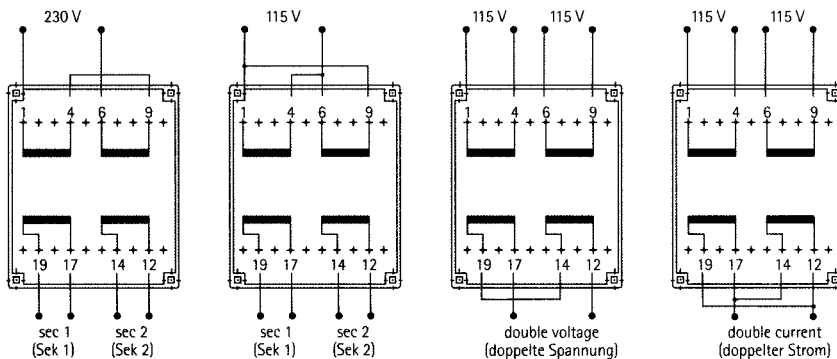

	Primary	Pin	Secondary	No-Load Voltage	Pin	Types Ref. No.	Approvals
	2x 115 V	1-4/9-6	6 V 1166 mA/ 6 V 1166 mA	7,80 V/ 7,80 V	12-14/19-17	BV 039-5095.0 L	1 · 2 · 3 · 4 · 5 · 10
RS 207-5905	2x 115 V	1-4/9-6	9 V 777 mA/ 9 V 777 mA	11,20 V/11,20 V	12-14/19-17	BV 039-5098.0 L	1 · 2 · 3 · 4 · 5 · 10
RS 207-5911	2x 115 V	1-4/9-6	12 V 583 mA/12 V 583 mA	14,80 V/14,80 V	12-14/19-17	BV 039-5101.0 L	1 · 2 · 3 · 4 · 5 · 10
RS 207-5927	2x 115 V	1-4/9-6	15 V 466 mA/15 V 466 mA	18,80 V/18,80 V	12-14/19-17	BV 039-5104.0 L	1 · 2 · 3 · 4 · 5 · 10
RS 207-5933	2x 115 V	1-4/9-6	18 V 388 mA/18 V 388 mA	22,70 V/22,70 V	12-14/19-17	BV 039-5107.0 L	1 · 2 · 3 · 4 · 5 · 10
RS 207-5949	2x 115 V	1-4/9-6	21 V 333 mA/21 V 333 mA	24,80 V/24,80 V	12-14/19-17	BV 039-5110.0 L	1 · 2 · 3 · 4 · 5 · 10

Specifications subject to change without notice.

