




ENGLISH

Datasheet

Stock No: 522-535

RS Pro SY Control Cable, 2 Core, Polyvinyl Chloride PVC Sheath

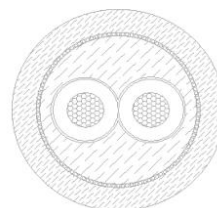

Conductor: Bare Copper
Conductor Dia. (mm): $0.25 \pm 0.008 \times 30$
Insulation: PVC
Insulation Dia. (mm): $2.8 \pm 0.1 \times 3C$
Filler: Chalk
Jacket 1: PVC
Outer Dia. (mm): 6.95 ± 0.2
Braid Shield: Galvanised Steel
Conductor Dia. (mm): 0.24
Conductor Qty: 24 x 3
Pitch(mm):
Coverage: 70%
Jacket: Trans PVC
Outer Dia. (mm): 10.03 ± 0.25

Colour:

The colour of the insulation: Blue , Brown ,
Yellow/Green

The jacket colour: Transparent

Description:

Rated Temperature (oC): -20 ~ 80

Rated Voltage (V): 300

Electrical Characteristics:

**Max.Conductor DC Resistance at
20°C (Ω /Km) :**

<13.7

**Min.Insulation DC Resistance at 20°C
($M\Omega \cdot KM$) :**

>500

Current Rating : 16 A