

## Verbatim LED MR16 GU5.3 5.5W 2700K Warm White 350 LM

- GU5.3 Socket
- 12 V AC/DC Voltage
- 20,000 hours Lifetime
- 84% Energy Saving
- Equivalent to 35W incandescent bulb

**Product Number** **52609**

### General Data

Lamp Socket GU5.3

### Electric Data

Wattage (W) 5.5

Wattage Equivalent (W) 35

Voltage (V) 12 V AC/DC

Dimmable no

Power Factor 0.50

Operating Frequency (Hz) 50-60

### Geometric Data

Length (mm) 49.8

Diameter (in mm) 49.8

Weight (g) 48

### Photometric Data

Luminous Flux 90° Cone (lm) 350

CRI  $\geq 80$

CCT (K) 2700


Luminous Intensity (cd) 750

Beam Angle (°) 35

Luminous Efficacy (lm/W) 63.6



Lifetime (hrs) 20,000

Switching Cycle 100,000

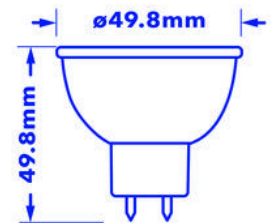


02/07/2014

### Photometric Diagrams

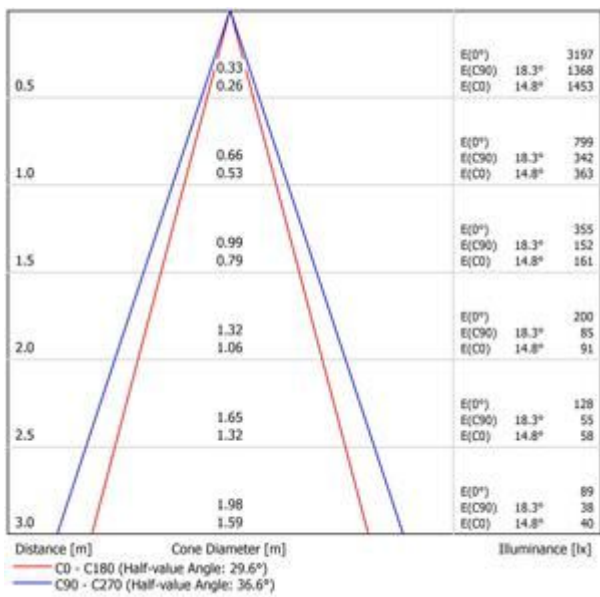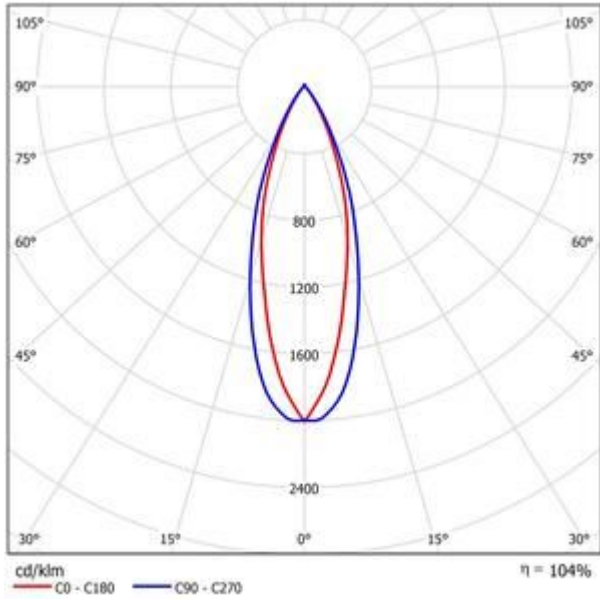

### Energy Rating

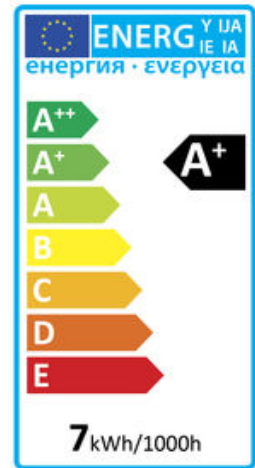

### Technical Packaging Details

**Barcode**

023942526094

**EAN 128**

(02)00023942526094(37)04(91)204

**EAN 14**

50023942526099

**Pack Dimensions(HxWxL)**

145 x 103 x 51

**Pack Weight**

72.5

**MOQ**

4

**Carton Dimensions (HxWxL)**

160 x 117 x 223

**Cartons/Pallet**

150

**Layers/Pallet**

5

**Units/Pallet**

600

02/07/2014