

This is a sample photo.


ORDER SYMBOL: PC 191913G

EL.number **EAN:** 6418074005403
 Sweden:
 Denmark:
 Finland: 3423701

INCLUDING:
 Enclosure body, cover, 4 slotted cover screws, and mounting screws.

APPROVALS:
 USA: UL Type 1, 3, 3S, 4, 4X, 12 (E75645 Vol.1 Sec.2); UL 94-V0
 EURO: IP 67; UL 94-V0
 OTHERS: IEC 529, CE, EEI, SETI 154171-01, CSA LR 49336-7

FIBOX SOLID PC

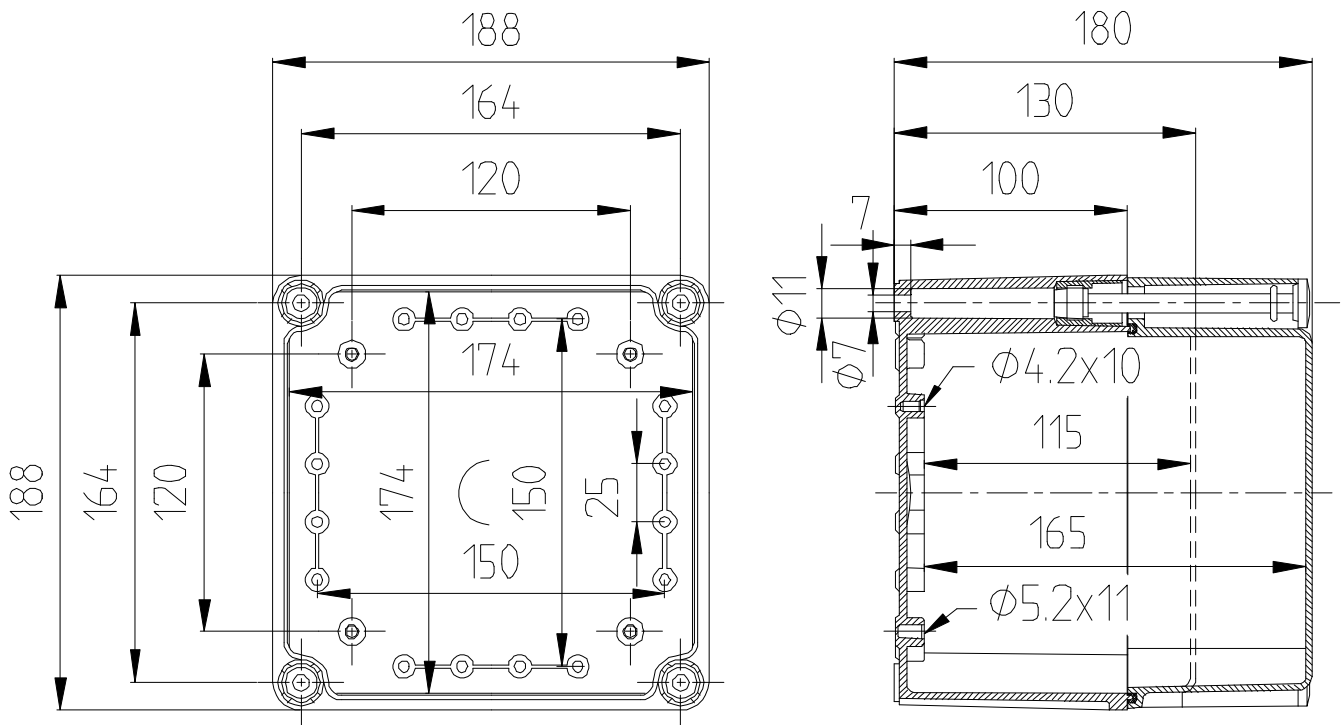

TECHNICAL INFORMATION:

Standard colour: RAL 7035
 Ingress protection: IP 67 (IEC 529)
 Flame resistance: UL 94-V2

Temp.range in cont. use: Max. +80 °C
 Temp. range of material: - 40 °C - + 120 °C

ACCESSORIES

Extension frame	EKJZR	DIN-Rail	EKV 32
Extension frame	EKMZR	DIN-Rail	EKV 34
Extension frame	EKOZR	Corner plug	MB 10523
Extension frame	EKPZR	Fastening lug	MB 10674
Extension frame	EKTZR	Earth bar support	MB 26069
Extension frame	EKUZR	Earth bar set	MR 26059
DIN-Rail	EKV 12		
DIN-Rail	EKV 14		
DIN-Rail	EKV 22		
DIN-Rail	EKV 24		