


P409, Film, Metallized Paper, Resistor/Capacitor, 0.22 uF, 20%, 630 VDC, 85°C, Lead Spacing = 20.3mm

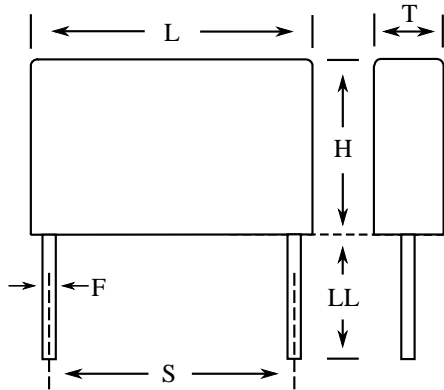

**Dimensions**

L	24mm MAX
H	16.5mm MAX
T	11.3mm MAX
S	20.3mm +/-0.4mm
LL	30mm +5mm
F	0.8mm +/-0.05mm

**Packaging Specifications**

<b>Packaging:</b>	Bulk, Bag
<b>Packaging Quantity:</b>	150

**General Information**

<b>Supplier:</b>	KEMET
<b>Series:</b>	P409
<b>Dielectric:</b>	Metallized Paper
<b>Style:</b>	Radial
<b>Features:</b>	RC Unit approved
<b>RoHS:</b>	Yes
<b>Lead:</b>	Wire Leads
<b>Qualifications:</b>	ENEC, UL, cUL
<b>Construction:</b>	Molded
<b>Miscellaneous:</b>	Resistor Tolerance: +/-30%. Resistor= 47 Ohms

**Specifications**

<b>Capacitance:</b>	0.22 uF
<b>Capacitance Tolerance:</b>	20%
<b>Voltage AC:</b>	275 VAC
<b>Voltage DC:</b>	630 VDC
<b>Temperature Range:</b>	-40/+85C
<b>Rated Temperature:</b>	85°C
<b>Insulation Resistance:</b>	3 GOhms
<b>Safety Class:</b>	X2