

Product selected: Capsule 12V 10W LP G4

Low voltage (12V) halogen capsule lamps offer compact size, high-performance and versatility, with three times the life of traditional incandescent lamps and constant light output throughout lamp life. These lamps are designed for use in luminaires with a protective front glass.

Applications

- Interior display, shop window, restaurant and discotheque lighting
- Precision task lighting

Features

- Compact size for optimum luminaire design
- Platinum coated pins (75W & 100W)
- Dimmable using a suitable dimmer for operation with a transformer
- Constant light output throughout lamp life
- The use of UV-Stop materials dramatically reduces UV emissions
- Average rated life: 3000 hours

Directions for use

- Must be used in luminaires with protective front glass
- Do not touch the quartz envelope with bare fingers


Product Attributes

Item description	Capsule 12V 10W LP G4
Ordering Code	0022241
EAN Code	5410288222417
Bulb shape	Capsule
Bulb finish / Light colour	Clear
Nominal wattage (W)	10
Rated wattage at 50 Hz (W)	10
Equivalent Inc. Lamp power (W)	-
Lamp power factor	1
Cap	G4
Dimmable	Yes
Nominal Voltage (V)	12
Nominal average life (h)	2000
Rated lamp life (h)	2000
Bulb finish / Light colour	Clear
Colour temperature (K)	2800
Nominal luminous flux at 25°C (lm)	100
Rated luminous flux at 25°C (lm)	100
Lumen maintenance at end nom. Life (%)	75
Maximum Lamp length L [mm]	33
Diameter D [mm]	9
Mercury content per lamp [mg]	0,0
Starting time (sec)	0.01
Warm-up time to 60% of full light	Instant full light
No. Of switching cycles before premature failures	> 8000 x
Optimal operating conditions	25°C
Packing Quantity	50


Product Image



Product line drawing (image)

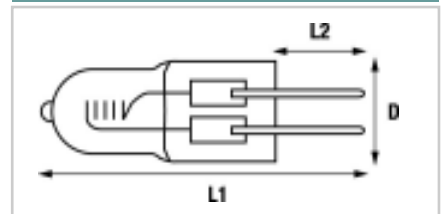

Cap (image)

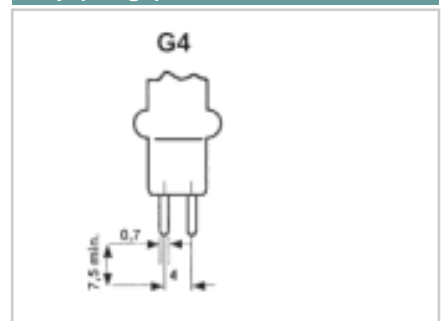

Fixture rating

