




Sample photo

Order symbol: CAB P 705027
Product nbr: 8104307
Description: Polyester cabinet
Remarks: Grey door

EAN: 6418074050045
El. number:
 Finland 3424141
 Denmark 8212018044
 Sweden 2539825

Including: Cabinet base, door with PUR gasket, 3mm double bit lock(s) with transport and plastic key, screws for mounting plate/DIN-rail and wall fastening lugs with screws. Wall mounting screws not supplied.

Dimensions:		L	W	H	Rating:
mm:	700	500	270	Ingress Protection (EN 60529): IP 66	
inch:	27.6	19.7	10.6	Impact Resistance (EN 50102): IK 10	
Materials:					Electrical insulation: Totally insulated
Material:	GRP				UV resistance: UL 508
Base colour:	RAL 7032				Flammability Rating (UL 746 C 5): UL 94 5V
Cover colour:	RAL 7032				Glow Wire Test (IEC 695-2-1) °C: 960
Cover screws material:	Stainless steel				UL Type: UL TYPE 3, 3R, 3S, 4, 4X, 12, 13
Gasket material:	Polyurethane				Certificates:
Temperatures:					
Short term:	-50 ... 150 °C				
Continuous:	-40 ... 70 °C				
Short term:	-60 ... 302 °F				
Continuous:	-40 ... 158 °F				
Accessories:					
MP 7050	Mounting plate				

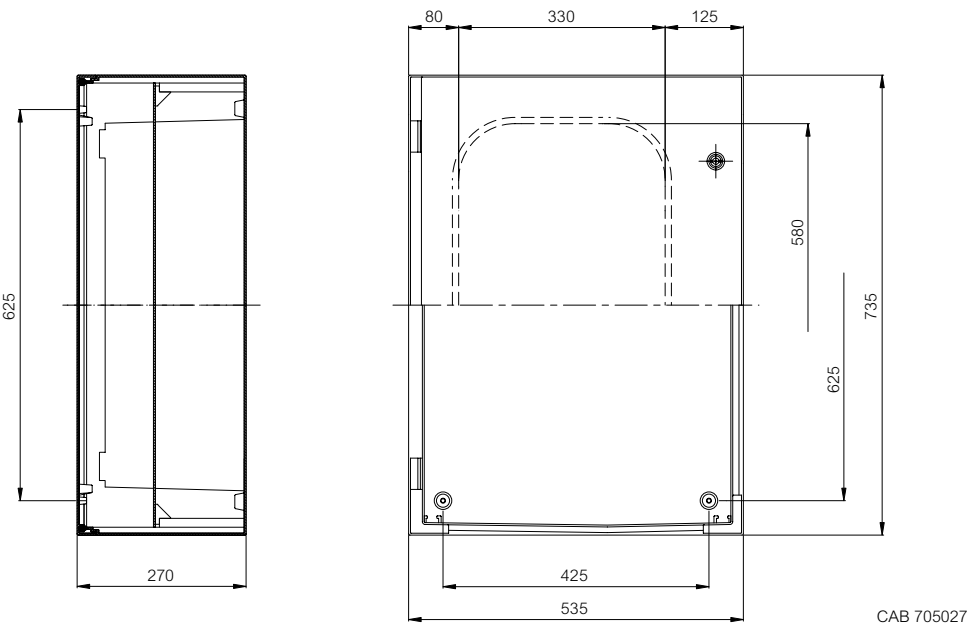

CAB 705027