


Verbatim LED PAR16 GU10 5W 2700K Warm White 350 LM

- GU10 Socket
- 220 - 240 V Voltage
- 20,000 hours Lifetime
- 90% Energy Saving
- Equivalent to 51W incandescent bulb


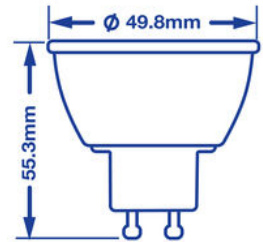


| Product Number | 52608 |
|-----------------------------|-------------|
| General Data | |
| Lamp Socket | GU10 |
| Electric Data | |
| Wattage (W) | 5 |
| Wattage Equivalent (W) | 51 |
| Voltage (V) | 220 - 240 V |
| Dimmable | no |
| Power Factor | 0.40 |
| Operating Frequency (Hz) | 50-60 |
| Geometric Data | |
| Length (mm) | 55.3 |
| Diameter (in mm) | 49.8 |
| Weight (g) | 57 |
| Photometric Data | |
| Luminous Flux 90° Cone (lm) | 350 |
| CRI | 80 |
| CCT (K) | 2700 |
| Luminous Intensity (cd) | 750 |
| Beam Angle (°) | 35 |
| Luminous Efficacy (lm/W) | 70 |
| Lifetime (hrs) | 20,000 |
| Switching Cycle | 100,000 |




02/07/2014

Photometric Diagrams

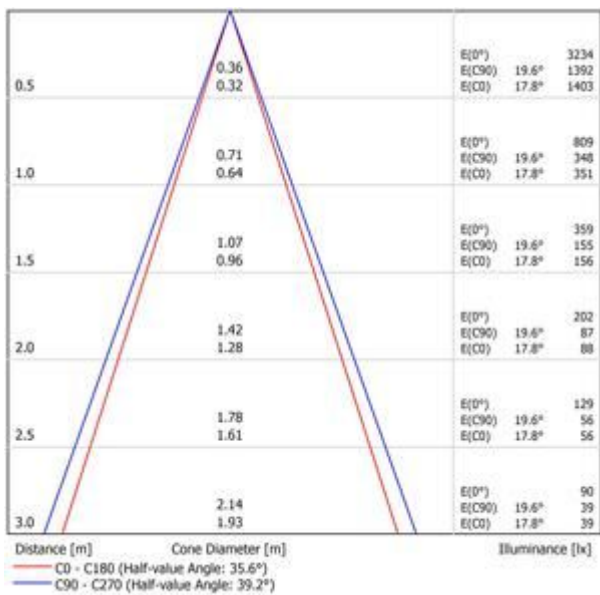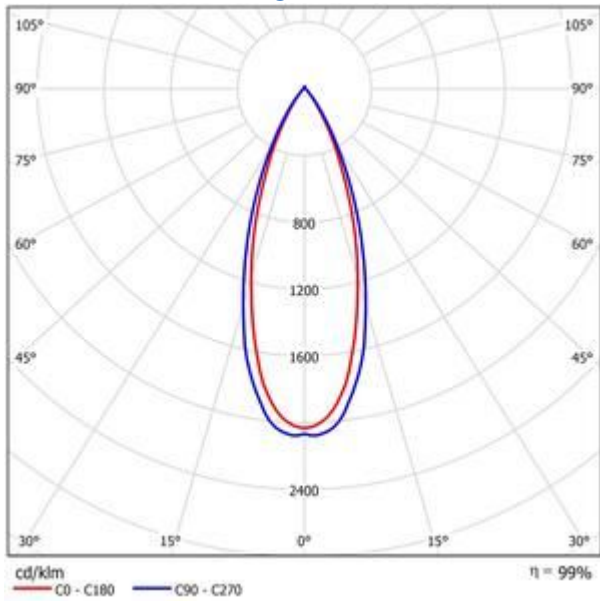

Energy Rating

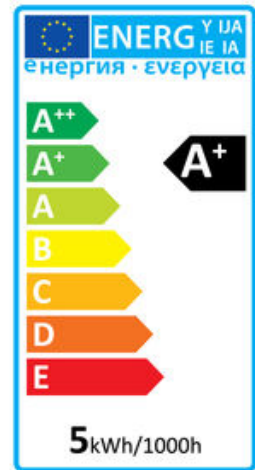

Technical Packaging Details

Barcode

023942526087

EAN 128

(02)00023942526087(37)04(91)204

EAN 14

50023942526082

Pack Dimensions(HxWxL)

145 x 103 x 51

Pack Weight

74

MOQ

4

Carton Dimensions (HxWxL)

160 x 117 x 223

Cartons/Pallet

150

Layers/Pallet

5

Units/Pallet

600

02/07/2014