



All 3M Products Innovation Explore 3M

Search



United States [Change](#)


Electrical Commercial and Industrial

[Products](#) | [Documentation & Literature](#) | [News & Tradeshow](#)s | [Support](#) |

[United States](#) > [All 3M Products](#) > [Market Segments](#) > [Electronics, Electrical, and Communications](#) > [Electrical Products](#) > [Electrical Commercial and Industrial](#) > [Products](#) > _____

3M™ Highland™ Nylon Fully Insulated Female Disconnect Terminal FDI14-187Q, AWG 16-14, 25/bag

3M ID 80611602618 UPC# 00051128600009 3M Product Number FDI14-187Q

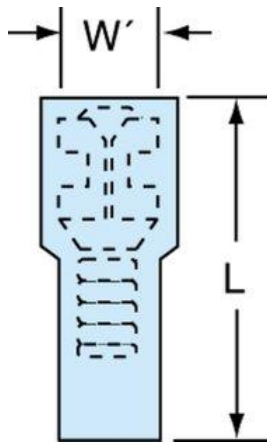

[Like](#)

This female disconnect accepts a wire range of 16-14 AWG, a .187 stud size and has a case quantity of 10 bags.

[Overview](#)

[Documentation](#)

Specifications

Agency Approvals	UL and CSA
Barrel Inside Diameter	0.085 Inch
Barrel Length	0.25 Inch
Barrel Style	Butted
Brand	Highland
Conductor Sizes	16 - 14 AWG
CSA File Number	LR22190
Diameter (D)	0.23 Inch
Fastener Orientation	Female
Insulation Material	Nylon
Length (L)	0.81 Inch
Mates with Male Tab Width (W')	0.187 Inch
Maximum Insulation Outer Diameter	0.145 Inch
Packaging	25 per bag
Pad Width	0.187 Inch
Terminal Style	Fully Insulated
Terminal Type	Disconnect
Thickness	0.02 Inch
UL File Number	E70512
Width (W)	0.3 Inch