
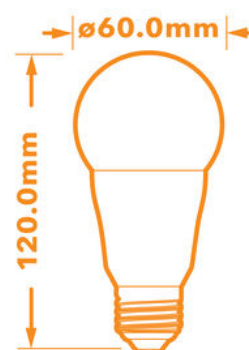


Verbatim LED Classic A E27 10W 2700K Warm White 730 LM DIM


- E27 Socket
- 220 - 240 V Voltage
- 30,000 hours Lifetime
- Dimmable
- 82% Energy Saving
- Lumen: 730
- Equivalent to 55W incandescent bulb

Product Number	52150
General Data	
Lamp Socket	E27
Electric Data	
Wattage (W)	10
Wattage Equivalent (W)	55
Voltage (V)	220 - 240 V
Dimmable	yes
Power Factor	0.90
Operating Frequency (Hz)	50-60
Geometric Data	
Length (mm)	120
Diameter (in mm)	60
Weight (g)	202.5
Photometric Data	
Luminous Flux (lm)	730
CRI	≥ 80
CCT (K)	2700
Beam Angle (°)	130
Luminous Efficacy (lm/W)	73
Lifetime (hrs)	30,000
Switching Cycle	20,000

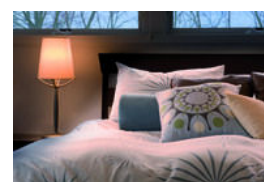

02/07/2014


Photometric Diagrams

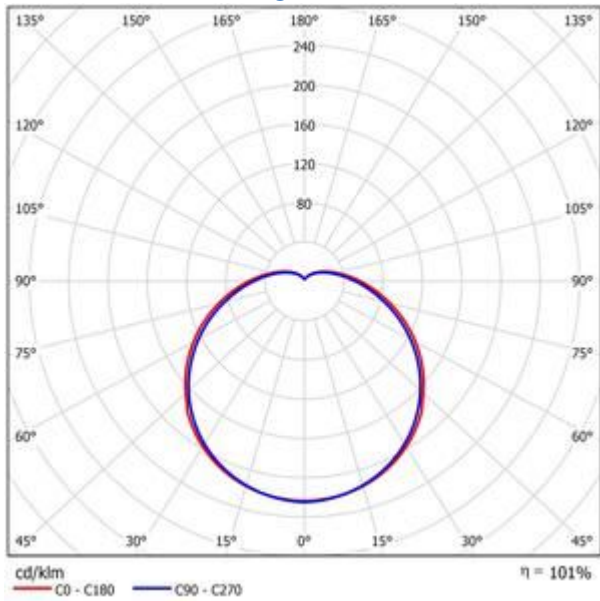

Distance [m]	Cone Diameter [m]	E(0°)	E(C90)	E(C0)	Illuminance [lx]
0.5	2.14 2.40	744	65.0° 28	67.4° 21	
1.0	4.29 4.80	186	65.0° 7	67.4° 5	
1.5	6.43 7.21	83	65.0° 3	67.4° 2	
2.0	8.58 9.61	47	65.0° 2	67.4° 1	
2.5	10.72 12.01	30	65.0° 1	67.4° 1	
3.0	12.87 14.41	21	65.0° 1	67.4° 1	

Distance [m] Cone Diameter [m] Illuminance [lx]
 — C0 - C180 (Half-value Angle: 134.8°)
 — C90 - C270 (Half-value Angle: 130.0°)

Energy Rating

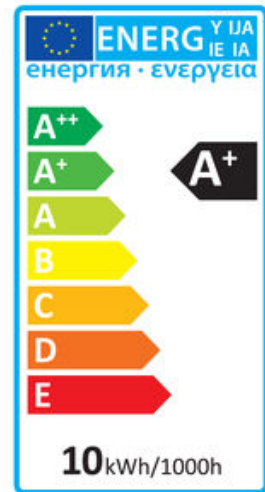

Technical Packaging Details

Barcode

023942521501

EAN 128

(02)00023942521501(37)04(91)204

EAN 14

50023942521506

Pack Dimensions(HxWxL)

178 x 118 x 61

Pack Weight

226

MOQ

4

Carton Dimensions (HxWxL)

195 x 144 x 253

Cartons/Pallet

80

Layers/Pallet

4

Units/Pallet

320

02/07/2014