


Part no. : 7607

Receptacle



switched, with mechanical DUO-interlock; can be padlocked

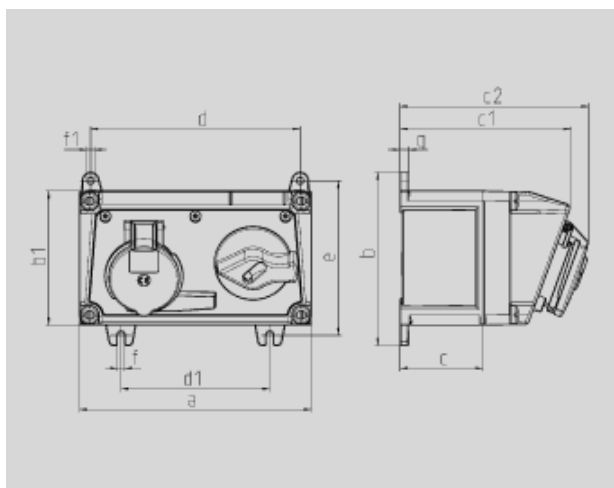

Drawing 1 MB 550	Amp. Poles	16			32		
		3	4	5	3	4	5
Dim. in mm	a	225	225	225	225	225	225
	b	168	168	168	168	168	168
	b1	130	130	130	130	130	130
	c	80	80	80	80	80	80
	c1	166	166	166	166	166	166
	c2	182	183	183	193	193	193
	d	204	204	204	204	204	204
	d1	145	145	145	145	145	145
	e	150	150	150	150	150	150
	f	7	7	7	7	7	7
	f1	Ø7	Ø7	Ø7	Ø7	Ø7	Ø7
	g	8	8	8	8	8	8

Article-group : **1100**

voltages : 400V

rated current : 16A

pole : 5 pole

IP protection types : 44

position of ground contact : 6h

weight : 1320

PART NUMBERS

		V	110V	230V	400V	500V	>50-500V
Hz			50,60	50,60	50,60	50,60	100-300 300-500
colour							
amp.							
16 A	3		7602	7603			
	4			7604	7605	7606	
	5				7607		
32 A	3		7611	7612			
	4			7613	7614	7615	
	5				7616		