

M 208-V0



Euromas
Enclosures, polycarbonate V0

Order no.: 02208094

Colour of enclosure group

Light grey, similar to RAL 7035; special colours on request

Protection class


Depending on the model: IP 65 or IP 66/DIN EN 60529; IP 67 available on request for some sizes.

Enclosure material

ABS, PC (UV stabilised) and selected sizes in PC UL 94 V0 (additional UL 94 V0 versions on request), seal made of CR; for details see Technical Information

Scope of delivery: Lid and base, lid screws made of V2A, self-tapping screws for mounting bosses

Note: V0 = version in UL 94 V0 enclosure material.
IP = Ingress protection acc. to DIN EN 60529

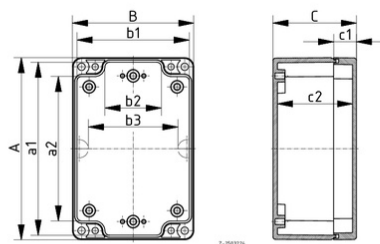

A	98 mm
B	64 mm
C	36,4 mm
a1	89,4 mm
a2	74 mm
b1	55,4 mm
b2	32 mm
c1	9,2 mm
c2	29,4 mm

Technical drawings

3D product data in STEP format:

[Registration necessary](#)

Basic drawing for processing work:

[02208094_M-208-V0-G.dxf](#) (332 KB)

Catalogue drawing in PDF format:

[02208094_M-208-V0.pdf](#) (89 KB)

Chapter download

[Euromas ABS PC GB.pdf](#) (338 KB)

Accessories



Rubber feet, plug-in

22003300

E

For M/T 208-260



Threaded inserts for mounting bosses

59002810

DODGE M3x6,5

ND = 4.0 x 6.5

59002820

DODGE M4x9,5

ND = 5.4 x 9.5

* = Available on request